





GE
Lighting

47683 - 65R40/FL/LL

GE soft white 65 watt R40 floodlight 1-pack

- Use original GE's Soft White when you need a light without glare and harsh shadows.
- GE's Floodlights cast a wider beam that adds drama to fireplaces, kitchen counters and entryways.
- 2600K soft white light appearance
- Estimated yearly energy costs \$7.83 based on 3 hours per day \$0.11 per kWh
- GE soft white indoor spotlights provide warm, pleasing everyday light without harsh glares and shadows. These bulbs' funnel shape and reflective coating help direct light where it is needed better than a standard incandescent bulb
- Lasts 2.3 years based on 3 hours per day usage
- R40 indoor floodlight with medium base for use in directional fixtures such as recessed can lighting
- 480 lumens providing cozy, relaxing™ light

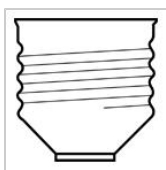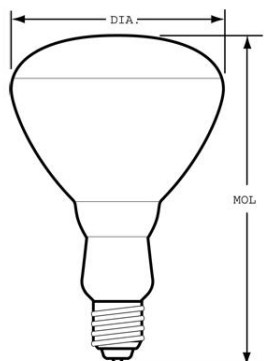

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - Reflector
Bulb	BR40
Base	Medium Screw (E26)
Filament	CC-6
Rated Life (NOM)	2500.0 h
Life in Years (NOM)	2.3
Primary Application	Indoor Floodlight

PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	480.0
Color Temperature (NOM)	2600.0 K

ELECTRICAL CHARACTERISTICS

Wattage (NOM)	65.0
Voltage (NOM)	120.0
Estimated Energy Cost per Year (NOM)	7.83

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	6.560 in(166.6 mm)
Bulb Diameter (DIA) (NOM)	5.000 in(127.0 mm)

PRODUCT INFORMATION

Product Code	47683
Description	65R40/FL/LL
Standard Package	BUNDLE
Standard Package GTIN	00043168476836
Standard Package Quantity	30
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	30
UPC	043168417990

CAUTIONS & WARNINGS

Warning

- Unexpected lamp rupture may cause injury, fire, or property damage
 - Avoid direct water, liquid or metal contact.
- Risk of Fire
 - Keep combustible materials away from lamp.
 - Use in fixture rated for this product.

*Twenty month life based on rated life at 4 hours/day. Provides nearly the same light output (650 lumens) as the 65 watt R40 Soft White (2000 hrs. rated life, 730 lumens).





GE
Lighting

47683 - 65R40/FL/LL

GE soft white 65 watt R40 floodlight 1-pack

- Use original GE's Soft White when you need a light without glare and harsh shadows.
- GE's Floodlights cast a wider beam that adds drama to fireplaces, kitchen counters and entryways.
- 2600K soft white light appearance
- Estimated yearly energy costs \$7.83 based on 3 hours per day \$0.11 per kWh
- GE soft white indoor spotlights provide warm, pleasing everyday light without harsh glares and shadows. These bulbs' funnel shape and reflective coating help direct light where it is needed better than a standard incandescent bulb
- Lasts 2.3 years based on 3 hours per day usage
- R40 indoor floodlight with medium base for use in directional fixtures such as recessed can lighting
- 480 lumens providing cozy, relaxing™ light

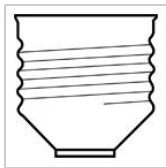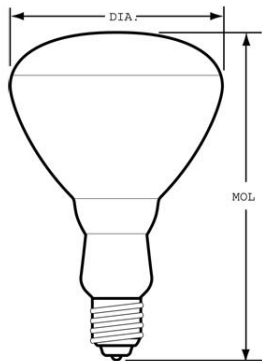

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - Reflector
Bulb	BR40
Base	Medium Screw (E26)
Filament	CC-6
Rated Life (NOM)	2500.0 h
Life in Years (NOM)	2.3
Primary Application	Indoor Floodlight

PHOTOMETRIC CHARACTERISTICS

Initial Lumens (NOM)	480.0
Color Temperature (NOM)	2600.0 K

ELECTRICAL CHARACTERISTICS

Wattage (NOM)	65.0
Voltage (NOM)	120.0
Estimated Energy Cost per Year (NOM)	7.83

DIMENSIONS

Maximum Overall Length (MOL) (NOM)	6.560 in(166.6 mm)
Bulb Diameter (DIA) (NOM)	5.000 in(127.0 mm)

PRODUCT INFORMATION

Product Code	47683
Description	65R40/FL/LL
Standard Package	BUNDLE
Standard Package GTIN	00043168476836
Standard Package Quantity	30
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	30
UPC	043168417990

CAUTIONS & WARNINGS

Warning

- Unexpected lamp rupture may cause injury, fire, or property damage
 - Avoid direct water, liquid or metal contact.
- Risk of Fire
 - Keep combustible materials away from lamp.
 - Use in fixture rated for this product.

*Twenty month life based on rated life at 4 hours/day. Provides nearly the same light output (650 lumens) as the 65 watt R40 Soft White (2000 hrs. rated life, 730 lumens).