



# ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

3804 South Street  
75964-7263, TX Nacogdoches  
Phone: 936-569-7941  
Fax: 936-560-4685

## 66PT78 Bit, Naileater 7/8(.875) X 18 (66PT-7/8)

*Greenlee Textron*

Catalog Number	66PT78
Manufacturer	Greenlee Textron
Description	Power Bit, Self Feeding Screw Point; Diameter 7/8 Inch; 18 Inch Overall Length; 15 Inch Twist Length; Hex Shank Type; 7/16 Inch Shank Size; Heat Treated Steel Material; Nail Eater II[R] Brand; 66PT Model; Flute Type Twist; Packaging Type P.O.P
Weight per unit	1.4 (lbs/each)
Product Category	Bits, Parts, Accessories

### Features

Drill Size	7/8 INCH
Flute Length	15 INCH
Flute Type	TWIST
Material	Steel IN
Process	HEAT TREATED
Shank Size	7/16 INCH
Shank Type	HEX
Twist Length	15 INCH

### Dimensions and Weight

Diameter	7/8 INCH
Overall Length	18 INCH

### Descriptions

Additional Information	FLUTE TYPE TWIST; PACKAGING TYPE P.O.P; WEIGHT 1.5 LB
Commodity Description	POWER TOOLS BITS, PARTS, ACCESSORIES
Description	BIT,NAILEATER 7/8(.875) X 18 (66PT-7/8)
Long Description	POWER BIT, SELF FEEDING SCREW POINT; DIAMETER 7/8 INCH; 18 INCH OVERALL LENGTH; 15 INCH TWIST LENGTH; HEX SHANK TYPE; 7/16 INCH SHANK SIZE; HEAT TREATED STEEL MATERIAL; NAIL EATER II[R] BRAND; 66PT MODEL; FLUTE TYPE TWIST; PACKAGING TYPE P.O.P
Product Type	Auger Drill Bit

### Manufacturer Information

Brand	Greenlee Textron
GTIN	00783310309277
Manufacturers Part Number	66PT-7/8
Model	66PT
UPC	783310309277

### Taxonomies, Classifications, and Categories

Category Description	BITS, BLADES, AND HOLE SAWS
Type	SELF FEEDING SCREW POINT



# ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service


3804 South Street  
75964-7263, TX Nacogdoches  
Phone: 936-569-7941  
Fax: 936-560-4685

## Packaging

Carton	1
Weight Per each	1.35

## Bit Extensions

- Extend bit lengths - Holesaw arbors, spade bits, Nail Eater II® bits, Electrician's bits and Step bits.
- Use to bore deeper in wood.

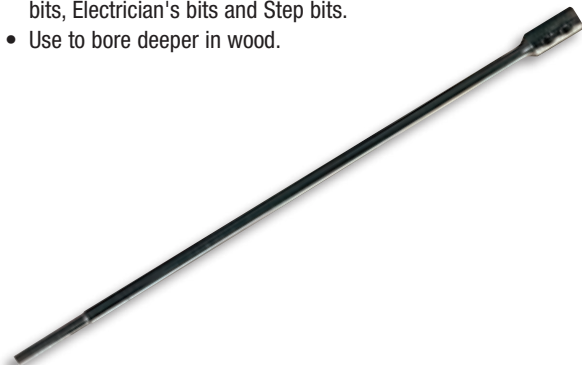

CAT. NO.	UPC NO.	DESCRIPTION
3713GB	50962	Set Screw for 901-12/02706
3678GB	50753	Set Screw for 902-18/02707 and 902-24/02708
3693GB	50765	Set Screw for 904-5-1/2/34996
53892	53892	Set Screw for 904H-12/34980, 904H-18/35356 and 904H-24/35358
51376	51376	Allen Wrench for use with set screws for 901-12/02706, 902-18/02707 and 902-24/02708
52144	52144	Allen Wrench for use with set screws for 904-5-1/2/34996

CAT. NO.	UPC NO.	LENGTH		HEX SHANK		HOLE DIA.		HEAD DIA.		WEIGHT	
		INCH	mm	INCH	mm	INCH	mm	INCH	mm	LBS.	g
901-12	02706	12	304.8	1/4	6.4	1/4	6.4	9/16	14.3	1.4	636
902-18	02707	18	457.2	5/16	7.9	23/64	9.1	21/32	16.7	2.5	1134
902-24	02708	24	609.6	5/16	7.9	23/64	9.1	21/32	16.7	3.4	1543
904-5-1/2	34996	5-1/2	139.7	7/16	11.1	1/2	12.7	1	25.4	2.1	953
904H-12	34980	12	304.8	7/16	11.1	**		23/32	18.3	2.9	1316
904H-18	35356	18	457.2	7/16	11.1	**		23/32	18.3	4.3	1951
904H-24	35358	24	609.6	7/16	11.1	**		23/32	18.3	5	2268

\*\*For 7/16" Hex or 1/2" Round with 3 Flats, 1/4" Wide

BIT EXTENSION	HEX SHANK		USE WITH
	INCH	mm	
901-12	1/4	6.4	33A-5/16 through 33A-1-1/2 and 37157 arbor. 34A-3/8 through 34A-1.
902-18 and 902-24	5/16	7.9	18-5/8 through 18-1; 45-5/8 through 45-13/16; 61PTS-5/8 through 61PTS-1; 66PT-3/8 through 66PT-9/16 and 37154 and 38522 arbors.
904 through 904H	7/16	11.1	18-1-1/8 through 18-1-1/4; 45-7/8 through 45-1-1/2; 61/62PTS-1-1/8 and 61/62PTS-1-1/2; 62PTS-5/8 through 62PTS-1; 66PT-3/4 through 66PT-1-1/2 and 149G-1 through 149G-3 and 37155 and 37156 arbors.

## Nail Eater II® Wood Boring Bits



- Patented new design for improved cutting and cleaner holes.
- Self-feeding screw point draws bit through wood.
- Unique patented design cutting angle - smoother starts, reduced cutting loads.
- Made of super tough, heat-treated steel; cuts through nails and provides longer life.
- "Shorty" bits - for working in tight places, yet still can go through three abutting 2 x 4s.
- See "Bit Extensions" if more length is required (see above).
- P.O.P packaged

### SPECIFICATIONS

61 PTS SHORTY NAIL EATER II®, 62 PTS AND 61/62 BIG SHANK SHORTY NAIL EATER II® BITS	
Overall Length	7-5/8" (193.7 mm)
Twist Length	5" (127 mm)
Electric drill required	61 PTS - 5/8" through 61 PTS - 1", minimum 3/8" drill; All Big Shank, 1/2" drill.
66 PT NAIL EATER II® BITS	
Overall Length	18" (457.2 mm)
Twist Length	15" (381 mm)

### 61PTS SHORTY, 62PTS AND 61/62 PTS BIG SHANK SHORTY NAIL EATER II® BITS

CAT. NO.	POP UPC NO.	BULK UPC NO.	HOLE DIA.		HEX SHANK		WEIGHT	
			INCH	mm	INCH	mm	LBS.	g
61PTS-5/8	30419	—	5/8	15.9	5/16	7.9	.3	137
61PTS-3/4	30423	—	3/4	19.1	5/16	7.9	.4	182
61PTS-7/8	30427	—	7/8	22.2	5/16	7.9	.5	227
61PTS-1	30429	—	1	25.4	5/16	7.9	.8	363
62PTS-5/8	31788	—	5/8	15.9	7/16	11.1	.3	137
62PTS-11/16	31790	—	11/16	17.5	7/16	11.1	.4	182
62PTS-3/4	31792	36640	3/4	19.1	7/16	11.1	.5	227
62PTS-13/16	31794	—	13/16	20.6	7/16	11.1	.5	227
62PTS-7/8	31796	36642	7/8	22.2	7/16	11.1	.6	273
62PTS-1	31798	36643	1	25.4	7/16	11.1	.7	318
61/62PTS-1-1/8	30431	—	1-1/8	28.6	7/16	11.1	.9	409
61/62PTS-1-1/4	30433	—	1-1/4	31.8	7/16	11.1	1.1	499

### 66PT NAIL EATER II® BITS

CAT. NO.	POP UPC NO.	BULK UPC NO.	HOLE DIA.		HEX SHANK		WEIGHT	
			INCH	mm	INCH	mm	LBS.	g
66PT-1/2	30915	—	1/2	12.7	5/16	7.9	.7	318
66PT-5/8	30919	—	5/8	15.9	7/16	11.1	.8	363
66PT-11/16	30921	—	11/16	17.5	7/16	11.1	1	454
66PT-3/4	30923	36659	3/4	19.1	7/16	11.1	1.2	545
66PT-13/16	30925	—	13/16	20.6	7/16	11.1	1.2	545
66PT-7/8	30927	36662	7/8	22.2	7/16	11.1	1.5	681
66PT-15/16	30929	—	15/16	23.8	7/16	11.1	1.6	726
66PT-1	30931	36664	1	25.4	7/16	11.1	1.8	817
66PT-1-1/8	30935	—	1-1/8	28.6	7/16	11.1	2.3	1044
66PT-1-1/4	30937	—	1-1/4	31.8	7/16	11.1	2.8	1270