

Superstrut[®]

Pipe Straps, Pipe Clamps & Hangers (Series 700)

T&B Catalog Number:

702 2 1/2 HDG

UPC Number:

61601314075

Status:

Active

Description:

Strap, 12 Gauge, Size 2-1/2 Inch, Outer Diameter Size 2.875 Inches, Hot-Dip Galvanized Steel, For Rigid or IMC Conduit, Pipe and Electrical Metal Tubing

Features

Bolt head is combination slot and hex head for flexibility of attachment

Square nut is captivated on the shoulder for easy one-handed tightening.

Straps are interchangeable with 1-1/2 in. strut, for broader application.

Straps are shipped assembled so counting and sorting are easier.

Pipe and conduit sizes are shown on the strap for easy identification.

Application

Superstrut Pipe Straps are designed to be twist inserted anywhere along the slot side of the channel.

General

Trade Size (inches)	2 1/2
Material	Steel
Finish	Hot-Dip Galvanized
Design Load (lbs)	1000
Safety Factor	3

Dimension Information

Rigid Conduit Size (inches)	2 1/2
Material Thickness (ga.)	12
Outside Diameter (inches)	2.875

Packaging



Package in Units	50
T&B Sold in UOM	Each
T&B Weight Per UOM	37.5 lbs. per 100

Application Support

Metal Framing Channels-Series 1000	Available on Website
Finishes	Available on Website
Pipes-Clamps & Hangers-Series 700	Available on Website

Certifications

RoHS Compliance	Yes
-----------------	-----

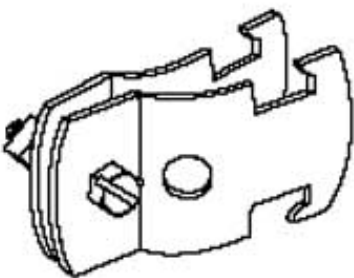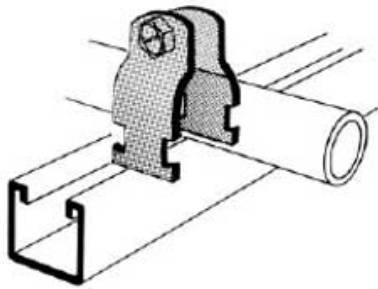

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.

T&B Technical Support
MS 3B-50

Hours: 7AM - 6PM CDT
Monday-Friday

Memphis, TN 38125
www.tnb.com

8155 T&B Blvd.
Memphis, TN 38125

Phone: (888) 862-3289
Fax: (901) 252-1321
Email:techsupport@tnb.com