




GE  
Lighting

### 63005 - 72A/W/H-2PK

#### GE energy-efficient soft white 72 watt A19 2-pack

• GE energy-efficient soft white bulbs have the same look, feel and nearly the same brightness as traditional incandescents, but with one big change: it now pays you back! These bulbs use 28% less energy than regular incandescents, helping you save money on energy costs. Use general purpose GE energy-efficient soft white bulbs in common household fixtures like table lamps, floor lamps, enclosed ceiling fixtures and bare lamp sockets

- A19 shape with medium base for use in table lamps and enclosed fixtures
- Estimated yearly energy costs \$8.67 based on 3 hours per day \$0.11 per kWh
- Lasts 0.9 years based on 3 hours per day usage
- 100 watt replacement uses only 72 watts

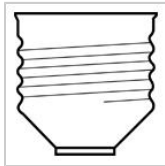

#### GENERAL CHARACTERISTICS

Lamp Type	Halogen - A-line
Bulb	A19
Base	Medium Screw (E26)
Filament	CC-8
Bulb Finish	Soft white
Rated Life	1000.0 hrs
Bulb Material	Sodalime glass
Base Material	Aluminium
Additional Info	soft white
Primary Application	Standard

#### PHOTOMETRIC CHARACTERISTICS

Initial Lumens	1490.0
Color Temperature	3000.0 K
Color Rendering Index (CRI)	100.0
Nominal Initial Lumens per Watt	20

#### ELECTRICAL CHARACTERISTICS

Wattage	72.0
Voltage	120.0
Burn Position	Universal burning position

#### DIMENSIONS

Maximum Overall Length (MOL)	4.4300 in(112.5 mm)
Bulb Diameter (DIA)	2.375 in(60.3 mm)

#### PRODUCT INFORMATION

Product Code	63005
Description	72A/W/H-2PK
Standard Package	Case
Standard Package GTIN	10043168630051
Standard Package Quantity	6
Sales Unit	Pallet
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	6
UPC	43168630054




GE  
Lighting

### 63005 - 72A/W/H-2PK

GE energy-efficient soft white 72 watt A19 2-pack

• GE energy-efficient soft white bulbs have the same look, feel and nearly the same brightness as traditional incandescents, but with one big change: it now pays you back! These bulbs use 28% less energy than regular incandescents, helping you save money on energy costs. Use general purpose GE energy-efficient soft white bulbs in common household fixtures like table lamps, floor lamps, enclosed ceiling fixtures and bare lamp sockets

- A19 shape with medium base for use in table lamps and enclosed fixtures
- Estimated yearly energy costs \$8.67 based on 3 hours per day \$0.11 per kWh
- Lasts 0.9 years based on 3 hours per day usage
- 100 watt replacement uses only 72 watts

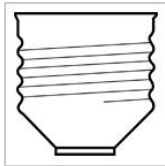

#### GENERAL CHARACTERISTICS

Lamp Type	Halogen - A-line
Bulb	A19
Base	Medium Screw (E26)
Filament	CC-8
Bulb Finish	Soft white
Rated Life	1000.0 hrs
Bulb Material	Sodalime glass
Base Material	Aluminium
Additional Info	soft white
Primary Application	Standard

#### PHOTOMETRIC CHARACTERISTICS

Initial Lumens	1490.0
Color Temperature	3000.0 K
Color Rendering Index (CRI)	100.0
Nominal Initial Lumens per Watt	20

#### ELECTRICAL CHARACTERISTICS

Wattage	72.0
Voltage	120.0
Burn Position	Universal burning position

#### DIMENSIONS

Maximum Overall Length (MOL)	4.4300 in(112.5 mm)
Bulb Diameter (DIA)	2.375 in(60.3 mm)

#### PRODUCT INFORMATION

Product Code	63005
Description	72A/W/H-2PK
Standard Package	Case
Standard Package GTIN	10043168630051
Standard Package Quantity	6
Sales Unit	Pallet
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	6
UPC	43168630054