


## Flush Indicator Lights

- Nylon body with flush transparent polycarbonate lens and stainless steel bezel, 94V-2 flammability rating
- 6 in. wire leads, 1/2 in. mounting diameter
- Lamp voltage is AC/DC
- Operating Temperature: Nylon Body: 140°C  
Polycarbonate lens: 135°C

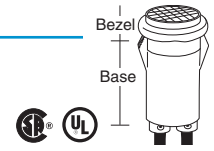


Product	Description	Lens Color	Lamp Voltage	Watts	Amp Rating	Average Life (hrs)	Lamp Type	Termination Style	Height (Base" × Bezel")	Cat. No.
	Flush Indicator Light	Red	14V	1.2	.08	50,000	Incandescent	6" Wire Leads	.91 × .10	775121*
	Flush Indicator Light	Red	28V	1.2	.04	25,000	Incandescent	6" Wire Leads	.91 × .10	776121*
	Flush Indicator Light	Red	125V	1/3	2mA Max.	25,000	Neon	6" Wire Leads	.91 × .10	777121*
	Flush Indicator Light	Green	125V	1/3	2mA Max.	15,000	Neon	6" Wire Leads	.91 × .10	777221*
	Flush Indicator Light	Amber	125V	1/3	2mA Max.	25,000	Neon	6" Wire Leads	.91 × .10	777321*
	Flush Indicator Light	Red	125V	1/3	2mA Max.	25,000	Neon	6" Wire Leads	.91 × .10	777212BK†

\*VDE certified

†Bulk Package of 100

## Raised Indicator Lights

- Nylon body with raised transparent polycarbonate lens and stainless steel bezel, 94V-2 flammability rating
- 1/2 in. mounting diameter
- Lamp voltage is AC/DC
- Operating Temperature: Nylon Body: 140°C  
Polycarbonate lens: 135°C

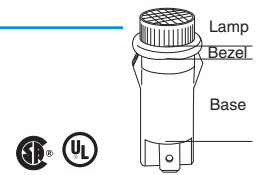

Product	Description	Lens Color	Lamp Voltage	Watts	Amp Rating	Average Life (hrs)	Lamp Type	Termination Style	Height (Base" × Bezel")	Cat. No.
	Raised Indicator Light	Red	14V	1.2	.08	50,000	Incandescent	6" Wire Leads	.91 × .10 × .20	775111*
	Raised Indicator Light	Red	28V	1.2	.04	25,000	Incandescent	6" Wire Leads	.91 × .10 × .20	776111*
	Raised Indicator Light	Green	28V	1.2	.04	25,000	Incandescent	6" Wire Leads	.91 × .10 × .20	776211*
	Raised Indicator Light	Amber	28V	1.2	.04	25,000	Incandescent	6" Wire Leads	.91 × .10 × .20	776311*
	Raised Indicator Light	Red	125V	1/3	2mA Max.	25,000	Neon	6" Wire Leads	.91 × .10 × .20	777111*
	Raised Indicator Light	Green	125V	1/3	2mA Max.	15,000	Neon	6" Wire Leads	.91 × .10 × .20	777211*
	Raised Indicator Light	Amber	125V	1/3	2mA Max.	25,000	Neon	6" Wire Leads	.91 × .10 × .20	777311*
	Raised Indicator Light	Blue	125V	1/3	2mA Max.	25,000	Neon	6" Wire Leads	.91 × .10 × .20	777411*
	Raised Indicator Light	Clear	125V	1/3	2mA Max.	25,000	Neon	6" Wire Leads	.91 × .10 × .20	777511*
	Raised Indicator Light	Red	250V	1/2	2mA Max.	25,000	Neon	6" Wire Leads	.91 × .10 × .20	778111*
	Raised Indicator Light	Green	250V	1/2	2mA Max.	15,000	Neon	6" Wire Leads	.91 × .10 × .20	778211*
		Raised Indicator Light	Green	28V	1.2	.04	25,000	Incandescent	.187" Spade	1.09 × .10 × .20
Raised Indicator Light		Red	28V	1.2	.04	25,000	Incandescent	.187" Spade	1.09 × .10 × .20	776112
Raised Indicator Light		Amber	28V	1.2	.04	25,000	Incandescent	.187" Spade	1.09 × .10 × .20	776312BK†
Raised Indicator Light		Red	125V	1/3	2mA Max.	25,000	Neon	.187" Spade	1.09 × .10 × .20	777112
Raised Indicator Light		Green	125V	1/3	2mA Max.	15,000	Neon	.187" Spade	1.09 × .10 × .20	777212
Raised Indicator Light		Amber	125V	1/3	2mA Max.	25,000	Neon	.187" Spade	1.09 × .10 × .20	777312BK†

\*VDE certified

†Bulk Package of 100