


90° - Large Size- Malleable

Images

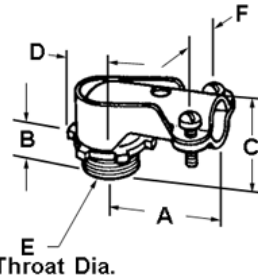

Throat Dia.

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-3/8
Dimension B in Inches: 1/2
Dimension C in Inches: 1-1/8
Dimension D in Inches: 1/2
Dimension E in Inches: .563
Dimension F in Inches: 15/16

Application

90 Degrees fitting with cover for connecting flexible metal conduit to box or enclosure.

Product Information

Material: Malleable Iron
Finish: Zinc electro-plate

Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39121419

Catalog ID: 801

UPC Number: 781747008015

Description: Connector, 90 Degrees, Malleable Iron, Flex Size 3/8 Inch

Application: 90 Degrees fitting with cover for connecting flexible metal conduit to box or enclosure.

Trade Size: 3/8"

Std Pkg Qty: 200

Unit Qty: 50