


90° Zinc

Images

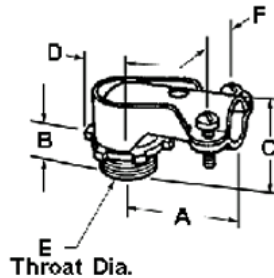

Throat Dia.

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-3/8

Dimension B in Inches: 5/8

Dimension C in Inches: 1-1/16

Dimension D in Inches: 1/2

Dimension E in Inches: .562

Dimension F in Inches: 15/16

Application

90 Degrees connector suitable for use to connect flexible metal conduit to box or enclosure. Insulator rated 105 degrees C. 12/2 (.560" 0 min) to 10/3 (.610" 0 max)

Product Information

Material: Zinc Die Cast

Finish: Ball burnished, mirror smooth

Certifications & Codes:

CSA File Number: LR39354

Federal Specification Number: A-A-50552

NEMA Standard: FB-1

UL File Number: E9391

UL Standard: UL-514B

UNSPSC: 39121419

Catalog ID: 801-DC12

UPC Number: 781747168016

Description: Connector, 90 Degrees, Zinc Die Cast, Insulated Throat, Flex Size 3/8 Inch

Application: 90 Degrees connector suitable for use to connect flexible metal conduit to box or enclosure. Insulator rated 105 degrees C. 12/2 (.560" 0 min) to 10/3 (.610" 0 max)

Trade Size: 1/2"

Country of Manufacture: USA

Std Pkg Qty: 250

Unit Qty: 25