



ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

2310 N. Stallings Dr.
75964-0000, TX Nacogdoches
Phone: 936-569-7941
Fax: 936-560-4685



804 1/2" Flex 90 Degree Malleable Iron Squeeze Conn

Bridgeport Fittings

Catalog Number	804
Manufacturer	Bridgeport Fittings
Description	90° Connector, 1/2 In Trade Size, Malleable Iron Material, Zinc Electroplated, 1-3/8 In Length, FMC Connection, 0.174 LB/Ea
Weight per unit	0.1740 (lbs/each)
Product Category	Liquid Tight Fittings

Features

angle	45 DEG
Connector Type	FMC
media	Yes

Dimensions and Weight

Size	1/2 In
------	--------

Descriptions

Description	1/2" FLEX 90 DEGREE MALLEABLE IRON SQUEEZE CONN
-------------	---

Manufacturer Information

Brand	Bridgeport
GTIN	00781747008046
UPC	781747008046

Taxonomies, Classifications, and Categories

Category Description	FLEX & MC FITTINGS
Type	CONNECTOR

Packaging


Carton	25
Package	100
Weight Per each	0.174

Uses, Certifications, and Standards

standard	UL,CSA
----------	--------

90° - Large Size- Malleable

Images

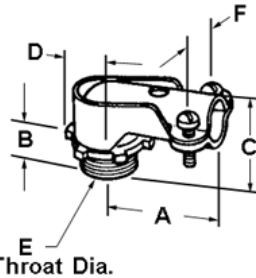

Throat Dia.

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-5/8
Dimension B in Inches: 3/8
Dimension C in Inches: 1-3/8
Dimension D in Inches: 1/2
Dimension E in Inches: .563
Dimension F in Inches: 15/16

Application

90 Degrees fitting with cover for connecting flexible metal conduit to box or enclosure.

Product Information

Material: Malleable Iron
Finish: Zinc electro-plate

Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39121419

Catalog ID: 804

UPC Number: 781747008046

Description: Connector, 90 Degrees, Malleable Iron, Flex Size 1/2 Inch

Application: 90 Degrees fitting with cover for connecting flexible metal conduit to box or enclosure.

Trade Size: 1/2"

Std Pkg Qty: 100

Unit Qty: 25