


## 90° - Large Size- Malleable

### Images

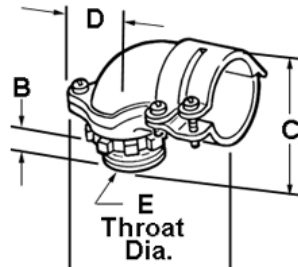

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-13/16  
Dimension B in Inches: 1/2  
Dimension C in Inches: 1-1/2  
Dimension D in Inches: 9/16  
Dimension E in Inches: .750  
Dimension F in Inches: 1-1/2

### Application

90 Degrees fitting with cover for connecting flexible metal conduit to box or enclosure.

### Product Information

Material: Malleable Iron  
Finish: Zinc electro-plate

### Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39121419

**Catalog ID:** 806

**UPC Number:** 781747008060

**Description:** Connector, 90 Degrees, Malleable Iron, Flex Size 3/4 Inch

**Application:** 90 Degrees fitting with cover for connecting flexible metal conduit to box or enclosure.

**Trade Size:** 3/4"

**Std Pkg Qty:** 50

**Unit Qty:** 10