


90° Zinc

Images

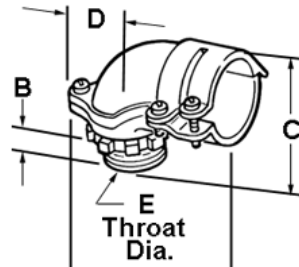

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-3/4

Dimension B in Inches: 1/2

Dimension C in Inches: 1-9/16

Dimension D in Inches: 5/8

Dimension E in Inches: 13/16

Dimension F in Inches: 1-1/2

Application

90 Degrees connector suitable to connect MC/FMC to box or enclosure. Insulator rated 105 degrees C. Diameter (.875" 0 min) to (1.00" 0 max)

Product Information

Material: Zinc Die Cast

Finish: Ball burnished, mirror smooth

Certifications & Codes:

CSA File Number: LR39354

Federal Specification Number: A-A-50552

NEMA Standard: FB-1

UL File Number: E20534

UL Standard: UL-514B

UNSPSC: 39121419

Catalog ID: 806-DC12

UPC Number: 781747168061

Description: Connector, 90 Degrees, Zinc Die Cast, Insulated Throat, Flex Size 3/4 Inch

Application: 90 Degrees connector suitable to connect MC/FMC to box or enclosure. Insulator rated 105 degrees C. Diameter (.875" 0 min) to (1.00" 0 max)

Trade Size: 3/4"

Country of Manufacture: USA

Std Pkg Qty: 50

Unit Qty: 10