


## 90° - Large Size- Malleable

### Images

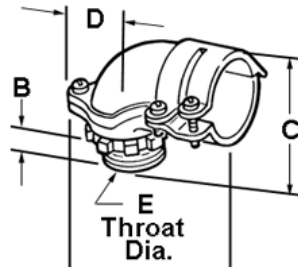

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 3-1/4  
Dimension B in Inches: 9/16  
Dimension C in Inches: 2-1/4  
Dimension D in Inches: 1  
Dimension E in Inches: 1-1/32

### Application

90 Degrees fitting with cover used for connecting flexible metal conduit to box or enclosure.

### Product Information

Material: Malleable Iron  
Finish: Zinc electro-plate

### Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39121419

**Catalog ID:** 807

**UPC Number:** 781747008077

**Description:** Connector, 90 Degrees, Malleable Iron, Size K.O. 1 Inch

**Application:** 90 Degrees fitting with cover used for connecting flexible metal conduit to box or enclosure.


**Trade Size:** 1"

**Std Pkg Qty:** 25

**Unit Qty:** 5

## 90° - Large Size- Malleable

### Images

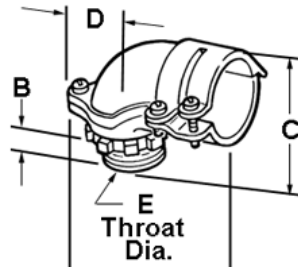

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 3-1/4  
Dimension B in Inches: 9/16  
Dimension C in Inches: 2-1/4  
Dimension D in Inches: 1  
Dimension E in Inches: 1-1/32

### Application

90 Degrees fitting with cover used for connecting flexible metal conduit to box or enclosure.

### Product Information

Material: Malleable Iron  
Finish: Zinc electro-plate

### Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39121419

**Catalog ID:** 807

**UPC Number:** 781747008077

**Description:** Connector, 90 Degrees, Malleable Iron, Size K.O. 1 Inch

**Application:** 90 Degrees fitting with cover used for connecting flexible metal conduit to box or enclosure.

**Trade Size:** 1"

**Std Pkg Qty:** 25

**Unit Qty:** 5