


90° Zinc

Images

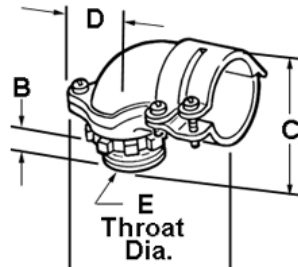

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 2-1/8
Dimension B in Inches: 9/16
Dimension C in Inches: 1-9/16
Dimension D in Inches: 3/4
Dimension E in Inches: 1.000
Dimension F in Inches: 2

Application

90 Degrees connector suitable for use to connect MC/FMC to box or enclosure. Insulator rated 105 degrees C. 1.187" 0 min to 1.312" 0 max

Product Information

Material: Zinc Die Cast
Finish: Ball burnished, mirror smooth

Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E20534
UL Standard:	UL-514B
UNSPSC:	39121419

Catalog ID: 807-DC12

UPC Number: 781747168078

Description: Connector, 90 Degrees, Zinc Die Cast, Insulated Throat, Flex Size 1 Inch

Application: 90 Degrees connector suitable for use to connect MC/FMC to box or enclosure. Insulator rated 105 degrees C. 1.187" 0 min to 1.312" 0 max

Trade Size: 1"

Country of Manufacture: USA

Std Pkg Qty: 25

Unit Qty: Bulk