


90° - Large Size- Malleable

Images

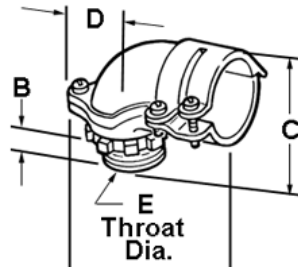

Application

90 Degrees fitting with cover used for connecting flexible metal conduit to box or enclosure.

Product Information

Material: Malleable Iron
Finish: Zinc electro-plate

Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39121419

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 4
Dimension B in Inches: 9/16
Dimension C in Inches: 2-7/8
Dimension D in Inches: 1-5/16
Dimension E in Inches: 1-3/8

Catalog ID: 808

UPC Number: 781747008084

Description: Connector, 90 Degrees, Malleable Iron, Size K.O. 1 1/4 Inch

Application: 90 Degrees fitting with cover used for connecting flexible metal conduit to box or enclosure.

Trade Size: 1-1/4"

Std Pkg Qty: 10

Unit Qty: ----