


90° Zinc

Images

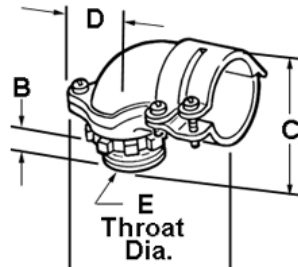

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 2-1/2

Dimension B in Inches: 5/8

Dimension C in Inches: 1-13/16

Dimension D in Inches: 15/16

Dimension E in Inches: 1.312

Dimension F in Inches: 2-1/2

Application

90 Degrees connector suitable for use to connect flexible metal conduit to box or enclosure. Insulator rated 105 degrees C. Diameter for 1.500" 0 min to 1.625" 0 max.

Product Information

Material: Zinc Die Cast

Finish: Ball burnished, mirror smooth

Certifications & Codes:

CSA File Number: LR39354

Federal Specification Number: A-A-50552

NEMA Standard: FB-1

UL File Number: E20534

UL Standard: UL-514B

UNSPSC: 39121419

Catalog ID: 808-DC12

UPC Number: 781747168085

Description: Connector, 90 Degrees, Zinc Die Cast, Insulated Throat, Flex Size 1 1/4 Inch

Application: 90 Degrees connector suitable for use to connect flexible metal conduit to box or enclosure. Insulator rated 105 degrees C. Diameter for 1.500" 0 min to 1.625" 0 max.

Trade Size: 1-1/4"

Country of Manufacture: USA

Std Pkg Qty: 25

Unit Qty: Bulk