


90° Zinc

Images

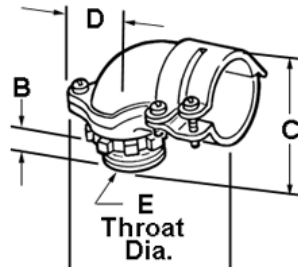

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 4-13/16
Dimension B in Inches: 3/4
Dimension C in Inches: 3-5/8
Dimension D in Inches: 1-3/8
Dimension E in Inches: 1.590
Dimension F in Inches: 3-5/8

Application

90 Degrees connector suitable for use to connect flexible metal conduit to box or enclosure. Insulator rated 105 degrees C.

Product Information

Material: Zinc Die Cast
Finish: Ball burnished, mirror smooth

Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39121419

Catalog ID: 809-DC12

UPC Number: 781747168092

Description: Connector, 90 Degrees, Zinc Die Cast, Insulated Throat, Flex Size 1 1/2 Inch

Application: 90 Degrees connector suitable for use to connect flexible metal conduit to box or enclosure. Insulator rated 105 degrees C.

Trade Size: 1-1/2"

Country of Manufacture: USA

Std Pkg Qty: 5

Unit Qty: Bulk