



ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

3804 South Street
75964-7263, TX Nacogdoches
Phone: 936-569-7941
Fax: 936-560-4685



812M24 SPST 1/2-3/4 Cond Snap Mount Clip

Erico, Inc. Eritec-Caddy

Catalog Number	812M24
Manufacturer	Erico, Inc. Eritec-Caddy
Description	Conduit/Pipe to Flange Clip, 812M24 Model, Spring Steel, Caddy Armour, 1/2 to 3/4 In Trade Size, 0.709 to 1.181 In (Od) Diameter, 0.09 LB
Weight per unit	0.0900 (lbs/each)
Product Category	Emt Fitting Tools & Accy.

Descriptions

Description	SPST 1/2-3/4 COND SNAP MOUNT CLIP
-------------	-----------------------------------

Manufacturer Information

Brand	nVent CADDY
GTIN	00782856162100
UPC	782856162100

Taxonomies, Classifications, and Categories

Category Description	CADDY (STRAPS ONLY)
Type	EM-M Conduit to Flange Clip

Packaging

Carton	100
Weight Per each	0.09


Uses, Certifications, and Standards

standard	cULus®
----------	--------

EM-M Conduit/Pipe to Flange Clip – 812M24



- Supports conduit/pipe or cable from beam flanges
- Snap close clip pivots a full 360°
- Requires only a hammer to install

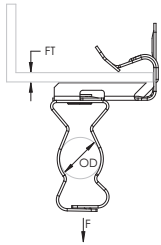

Part Number	812M24
Material	Spring Steel
Finish	nVent CADDY Armour
EMT Conduit Size	1/2" 3/4"
Rigid Conduit/Pipe Size	1/2" 3/4"
Outer Diameter (OD)	0.71" – 1.18"
Flange Thickness (FT)	1/8" – 1/4"
Static Load (F)	75 lb
Standard Packaging Quantity	100 pc
UPC	78285616210

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.erico.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

© 2018 nVent All rights reserved

nVent, nVent CADDY, nVent ERICO, nVent ERIFLEX and nVent LENTON are owned by nVent or its global affiliates.

All other trademarks are the property of their respective owners. nVent reserves the right to change specifications without prior notice.

