




RP

LIGHTING • FANS

Type:
Project:
Comments:
Prepared By:

Part #	8202HA
Category #:	8202
Family:	Recessed
Product Category:	Line Voltage Airtight Housing
Description:	4" IC Airtight Universal housing
Design Features	
Connectors	3 part quick connectors pre installed in all J Boxes
Construction	New construction
Thermal Protection	Protected against misuse of insulation and improper wiring
IC Rating	IC Rated for direct contact with Non-cellulose type insulation.
J Box	Listed for feed through wiring (4 in-4 out) and seven ½" knockouts
Bar hangers	Pre installed allowing for position at any point w/in a 24" joist span. Can be turned 90° on plaster frame, & to fit T-bar spine w/out additional clamps for use in drop ceilings.
Nails	Pre installed captive nails on bar hangers
Wattage	50W Max
Voltage	120V-60Hz
Warranty	1 year limited warranty
Material	
Frame	Steel
Listing	
ETL/UL	cETLus certified
Meets Washington's State energy code for restricted airflow	

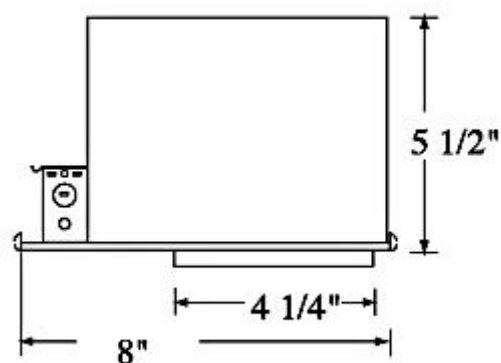

Trim Options

	Type	Item#	Finishes	O.D.
	Baffle 50W Max PAR20/R20	8701	Black, oil rubbed bronze & white	5"
	Shower Trim, Fresnel 30W Max, PAR20/R20	8702FS	Wet location listed. White	5"
	Reflector 50W Max, PAR20/R20	8703	Black, oil rubbed bronze & white Optional BA, BK, PB rings.	5"
	Satin Glass 30W Max, PAR20/R20	8704	Wet location listed White	5"
	Shower, Albalite 30W Max, PAR20/R20	8705AL	Wet location listed	5"
	Eyeball 50W Max, PAR20/R20	8706	White, Brushed Aluminum and black	5"
	Wall Wash 50W Max, PAR20/R20	8707	White	5"
	Satin Bubble Glass 30W Max, PAR20/R20	8710WH	Wet location listed White	5"
	Pin Hole 50W Max, PAR20/R20	8721PN	White	5"
	Gimbal 50W Max, PAR20/R20	8740	Brushed Aluminum, white, black	5"
	Open Shower Trim 50W Max, Outdoor rated, PAR20/R20	8714	White	5"

Additional Information

1. Socket is adjustable for proper positioning of different lamps types.
2. Adjusts to fit up to 1" ceiling thickness.
3. 5-1/2" height allows use in 2" x 6" joist construction.
4. Double Wall Construction