


Threaded - Both Ends

Images

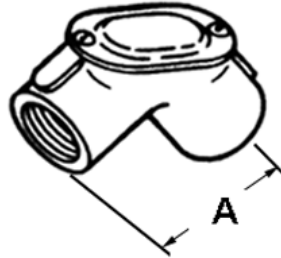

[Download Photo Image](#) [Download Dimensional Image](#)
Dimension A in Inches: 2"

Application

Used for connecting rigid or IMC to form 90 Degrees bend. Removable cover and neoprene gasket facilitate wire pulling.

Product Information

Material: Zinc Die Cast
Finish: Body: Ball burnished, mirror smooth,
Steel cover: Zinc electro-plate

Certifications & Codes:

Federal Specification Number:	A-A-50553
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39131717

Catalog ID: 83-DC

UPC Number: 781747090836

Description: Pull Elbow, Rigid to Rigid, Zinc Die Cast, Size 1 Inch

Application: Used for connecting rigid or IMC to form 90 Degrees bend. Removable cover and neoprene gasket facilitate wire pulling.

Trade Size: 1"

Std Pkg Qty: 25

Unit Qty: 5