


# Eaton 8450N

Catalog Number: 8450N

Eaton power device receptacle, #14 to 10 AWG, 50A, Flush, 250V, Back and side, Black, NEMA 15-50R, Three-pole, Four-wire, Three-pole, four-wire, grounding, Screw, Glass-filled nylon, Three-phase, Power

## General specifications

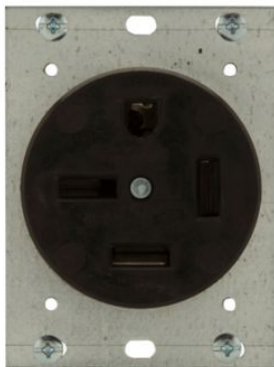

<b>Product Name</b>	<b>Catalog Number</b>
Eaton power device receptacle	8450N
<b>UPC</b>	<b>Product Length/Depth</b>
040893018638	3.25 in
<b>Product Height</b>	<b>Product Width</b>
2.38 in	2.94 in
<b>Product Weight</b>	<b>Compliances</b>
0.505 lb	RoHS Compliant

## Certifications

cULus Listed  
CSA Certified  
Federal Specification Classification 6233  
01

## Product specifications

### Phase

Three-phase

### Color

Black

### Wiring method

Back and side

### Material

Glass filled nylon

### Mounting method

Flush

### Allowable wire size

#14-10 AWG

### Amperage Rating

50 A

### Number Of Poles

Three-pole

### NEMA configuration

15-50R

### Design type

Receptacle

### Connection type

Screw

### Style

Power

### Number of wires

4

### Receptacle type

Three-pole, four-wire, grounding

### Voltage rating

250 V

### Torque rating

25 lbf-inch

## Resources

### Brochures

[Flush mount receptacles sell sheet](#)

### Catalogs

[Arrow Hart Buyers Guide Section A](#)

### Specifications and datasheets

[Eaton Specification Sheet - 8450N](#)



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com  
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)