


## Threaded - Both Ends

### Images

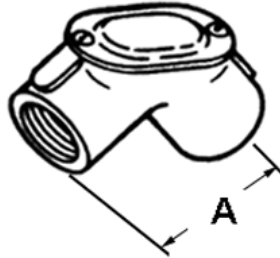

[Download Photo Image](#)   [Download Dimensional Image](#)  
Dimension A in Inches: 2-5/16

### Application

Used for connecting rigid or IMC to form 90 Degrees bend. Removable cover and neoprene gasket facilitate wire pulling.

### Product Information

Material: Zinc Die Cast  
Finish: Body: Ball burnished, mirror smooth,  
Steel cover: Zinc electro-plate

### Certifications & Codes:

Federal Specification Number:	A-A-50553
NEMA Standard:	FB-1
UL File Number:	E9391
UL Standard:	UL-514B
UNSPSC:	39131717

**Catalog ID:** 84-DC

**UPC Number:** 781747090843

**Description:** Pull Elbow, Rigid to Rigid, Zinc Die Cast, Size 1 1/4 Inch

**Application:** Used for connecting rigid or IMC to form 90 Degrees bend. Removable cover and neoprene gasket facilitate wire pulling.

**Trade Size:** 1 1/4"

**Std Pkg Qty:** 20

**Unit Qty:** 5