



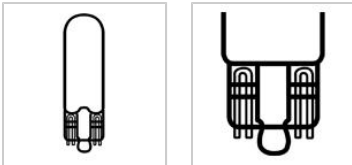

GE  
Lighting

**40969 - 85**

GE T1.75 (T1 3/4) - Low Voltage

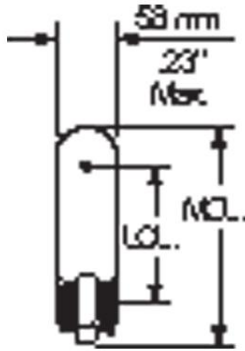

**GENERAL CHARACTERISTICS**

Lamp Type	Miniature - T & TL Shape
Bulb	T1.75 (T1 3/4)
Base	Wedge (W2.1x9.5d)
Filament	C-2F
Rated Life	7000.0 hrs
Atmosphere	Vacuum
Primary Application	Low Voltage

**PHOTOMETRIC CHARACTERISTICS**

Initial Lumens	4.0
Nominal Initial Lumens per Watt	4
Mean Spherical Candlepower (MSCP)	0.3

**ELECTRICAL CHARACTERISTICS**

Wattage	1.0
Voltage	28.0

**DIMENSIONS**

Maximum Overall Length (MOL)	0.8000 in(20.3 mm)
Bulb Diameter (DIA)	0.219 in(5.6 mm)
Light Center Length (LCL)	0.400 in(10.2 mm)

**PRODUCT INFORMATION**

Product Code	40969
Description	85
ANSI Code	85
Standard Package	Case
Standard Package GTIN	20043168409692
Standard Package Quantity	50
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	50
UPC	043168409698