




RP





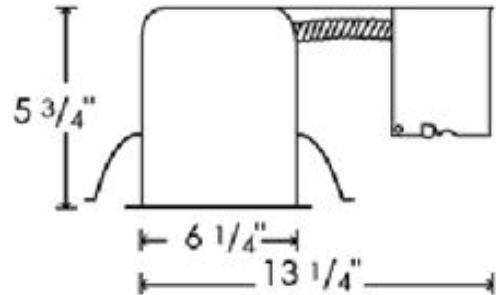


LIGHTING • FANS

Type:
Project:
Comments:
Prepared By:

Part #	8113HRICA
Description:	6" GU24 Shallow IC Airtight Compact remodel fluorescent housing
Design Features	
Thermal Protection	Protected against misuse of insulation and improper wiring
Construction	Remodel
IC Rating	IC rated for direct contact with non cellulose insulation
J Box	Listed for feed through wiring (4 in-4 out) and seven ½" knockouts & four non metallic cable knockouts w/ strain clamps
Connectors	3-port quick connectors
Lamp	Lamp variations (included) 8113HRICA-E1327 - 13W GU24 - 2700K 8113HRICA -E1341 - 13W GU24 - 4100K 8113HRICA -E1827 - 18W GU24 - 2700K 8113HRICA -E1841 - 18W GU24 - 4100K 8113HRICA -E2327 - 23W GU24 - 2700K 8113HRICA -E2341 - 23W GU24 - 4100K
Voltage	120V
Warranty	1 year limited warranty
Listing	
ETL/UL	cETLus for damp location
Meets Washington's State energy code for restricted airflow	



Trim Options

	Type	Item#	Finishes	O.D.
	Shower, Lexan, Fresnel Lens 60W Max, A19	8502FS	Wet location listed Metal trim ring available	6"
	Lexan Flat Opal Albalite Lens 40W Max, A19	8505AL	Wet location listed Metal trim ring available	6"
	Lexan Drop Opal 60W, A19	8509DR	Wet location listed Metal trim ring available	6"
	Wall Wash 60W Max, A19	8517WW		6"
	Cone, Specular	8518	White, Clear, & Brushed ALuminum Optional BA, BK rings	6"
	Cone	8532	White	6"
	Splay 40W Max, A19	8546	White	6"

Additional Information

1. Adjusts to fit up to 1" ceiling thickness.
2. 5-1/4" height allows use in 2" x 6" joist construction.