

# Switches TradeMaster® Decorator Switches


15A, 120 & 120/277VAC

Pass & Seymour




Switches


| Features   |  |
|--|--|
| <ul style="list-style-type: none"> <li>Designer-style satin-finish rocker.</li> <li>High-impact resistant thermoplastic construction.</li> <li>External screw-pressure-plate back and side wired. Accepts #12 and #14 AWG.</li> <li>Push wire #14 AWG.</li> <li>Narrow back body leaves more room for wires in the box.</li> </ul> | <ul style="list-style-type: none"> <li>Extra-long, through-body strap eliminates floating installations and imperfect applications.</li> <li>Smooth, quiet paddle action.</li> <li>Easy-access green hex head ground screw.</li> <li>Tri-drive ground, terminal and mounting screws.</li> <li>ON-OFF switches conform to NEC 430-104 requirements for kitchen disposal units.</li> </ul> |

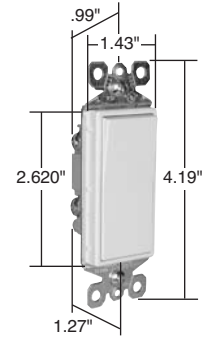


TM870-LA

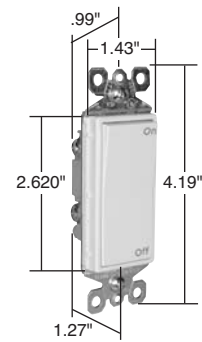

TM870-LAON

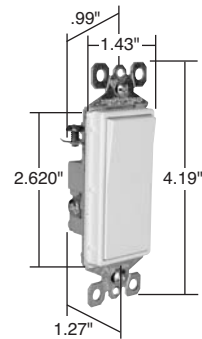

TM873-LA

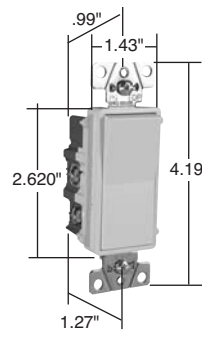

TM874-LA

| Catalog Number   | Rating<br>A. VAC | Color        | 3rd Party Compliance |                 |
|--|------------------|--------------|----------------------|-----------------|
|  |                  |              | UL<br>UL20           | CS<br>C22.2 111 |
| <b>Single Pole Decorator Switches Grounding*</b>                               |                  |              |                      |                 |
| TM870-I  | 15 120/277       | Ivory        | •                    | •               |
| TM870-W  | 15 120/277       | White        | •                    | •               |
| TM870  | 15 120/277       | Brown        | •                    | •               |
| TM870-GRY  | 15 120/277       | Gray         | •                    | •               |
| TM870-BK   | 15 120/277       | Black        | •                    | •               |
| TM870-LA   | 15 120/277       | Light Almond | •                    | •               |
| <b>Single Pole Decorator Switches Grounding with ON-OFF Indication</b>         |                  |              |                      |                 |
| TM870-ION  | 15 120/277       | Ivory        | •                    | •               |
| TM870-WON  | 15 120/277       | White        | •                    | •               |
| TM870-BKON   | 15 120/277       | Black        | •                    | •               |
| TM870-LAON   | 15 120/277       | Light Almond | •                    | •               |
| <b>Single Pole Illuminated Decorator Switches Grounding (Lighted when OFF)</b> |                  |              |                      |                 |
| TM870-ISL  | 15 120/277       | Ivory        | •                    | •               |
| TM870-WSL  | 15 120/277       | White        | •                    | •               |
| TM870-LASL   | 15 120/277       | Light Almond | •                    | •               |
| <b>Three-Way Decorator Switches Grounding*</b>                                 |                  |              |                      |                 |
| TM873-I  | 15 120/277       | Ivory        | •                    | •               |
| TM873-W  | 15 120/277       | White        | •                    | •               |
| TM873  | 15 120/277       | Brown        | •                    | •               |
| TM873-GRY  | 15 120/277       | Gray         | •                    | •               |
| TM873-BK   | 15 120/277       | Black        | •                    | •               |
| TM873-LA   | 15 120/277       | Light Almond | •                    | •               |
| <b>Three-Way Illuminated Decorator Switches Grounding (Lighted when OFF)</b>   |                  |              |                      |                 |
| TM873-ISL  | 15 120           | Ivory        | •                    | •               |
| TM873-WSL  | 15 120           | White        | •                    | •               |
| TM873-LASL   | 15 120           | Light Almond | •                    | •               |
| <b>Four-Way Decorator Switches Grounding</b>                                   |                  |              |                      |                 |
| TM874-I  | 15 120/277       | Ivory        | •                    | •               |
| TM874-W  | 15 120/277       | White        | •                    | •               |
| TM874  | 15 120/277       | Brown        | •                    | •               |
| TM874-BK   | 15 120/277       | Black        | •                    | •               |
| TM874-LA   | 15 120/277       | Light Almond | •                    | •               |

\*For Configurable Solutions, see Page U-1.

TradeMaster® Decorator Switches