



# ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

3804 South Street  
75964-7263, TX Nacogdoches  
Phone: 936-569-7941  
Fax: 936-560-4685



## 90680IV 600W Preset Slide Dimmer

*Pass & Seymour/Legrand*

Catalog Number	90680IV
Manufacturer	Pass & Seymour/Legrand
Description	Slide Dimmer, Wall Dimmer Type; 1.688 Inch W X 1.469 Inch D X 4.25 Inch H Size; Ivory Finish; Single Pole Operation Type; UL (Canada and Us) Approval; 120 V Voltage Rating; Visionpak Standard Package; 600 W Load Rating
Weight per unit	0.3400 (lbs/each)
Product Category	Lighting Dimmers

### Features

Load Rating	600 W
Load Type	INCANDESCENT
Operation Type	SINGLE POLE
Operator Type	SLIDE SWITCH WITH PRESET SWITCH
Voltage Rating	120 VAC AT 60 HZ
Wall Plate Type	Standard Decorator

### Material, Color, and Finish

Finish	IVORY
--------	-------

### Dimensions and Weight

Size	1.688 INCH W X 1.469 INCH D X 4.25 INCH H
------	---

### Descriptions

Additional Information	Grade Specification
Commodity Description	LIGHTING DIMMERS
Description	600W PRESET SLIDE DIMMER
Long Description	SLIDE DIMMER, WALL DIMMER TYPE; 1.688 INCH W X 1.469 INCH D X 4.25 INCH H SIZE; IVORY FINISH; SINGLE POLE OPERATION TYPE; UL (CANADA AND US) APPROVAL; 120 V VOLTAGE RATING; VISIONPAK STANDARD PACKAGE; 600 W LOAD RATING
Product Type	Slide Dimmer

### Manufacturer Information

Brand	Pass and Seymour
GTIN	00785007266061
Manufacturers Part Number	90680IV
Model	90680
UPC	785007266061

### Taxonomies, Classifications, and Categories

Category Description	Residential dimmers, motion sensors, controls, & photo cells
Type	WALL DIMMER



# ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

3804 South Street  
75964-7263, TX Nacogdoches  
Phone: 936-569-7941  
Fax: 936-560-4685

## Availability

Manufacturer Status	Non-Stock
Status	Inactive

## Packaging

Carton	1
Package	6
Standard Package	VISIONPAK[T]
Weight Per each	0.34

## Uses, Certifications, and Standards

Approval	UL, CSA
----------	---------



# Decorator Devices Wide Slide Series


Pass & Seymour




### Full-On Bypass

When the dimmer is placed in the full-On position, the dimming circuitry is bypassed by latching contacts. This feature allows for 100% lighting output and extends dimmer life by eliminating heat build-up.

Features	
<ul style="list-style-type: none"> <li>Maximum ratings are for continuous full load.</li> <li>Many 1000W models fit standard Decorator plates.</li> <li>RFI suppression built in.</li> <li>Full-On bypass.</li> </ul>	<ul style="list-style-type: none"> <li>Preset "ON/OFF" switch automatically returns controlled lights to preset level without readjusting dimmer setting.</li> <li>600W maximum rated dimmers can be ganged without de-rating.</li> </ul>

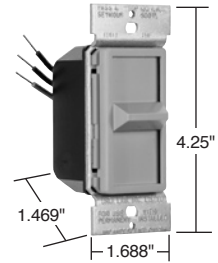

**P** 90680 **P** 90683  
**N** 90681

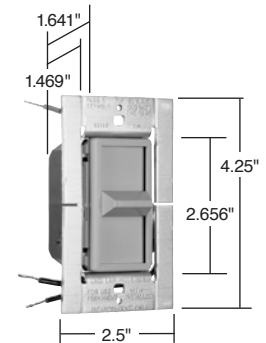

**P** 91180 **P** 91183  
**N** 91181

**P** = Preset  
**N** = Non-Preset

Catalog Number		Description	Ratings	Color
Single Pole	Three-Way			
<b>600W Incandescent Specification Grade Slide Dimmers</b>				
90680I* 90680W* 90680GRY 90680LA*	90683I* 90683W* 90683GRY 90683LA*	Preset	120V 600W max.	Ivory White Gray Light Almond
90681I* 90681W* 90681GRY 90681LA*		Non-Preset	120V 600W max.	Ivory White Gray Light Almond
<b>1000W Incandescent Specification Grade Slide Dimmers</b>				
91180I 91180W 91180GRY 91180LA	91183I 91183W 91183GRY 91183LA	Preset	120V 1000W max.	Ivory White Gray Light Almond
91181I 91181W 91181LA		Non-Preset	120V 1000W max.	Ivory White Light Almond

\* Available in VisionPak™ packaging, add "V" to Catalog Number. Example: 90680IV.

Max. Load Rating	Fins Removed	
	One Side	Two Side
<b>De-Rating Chart</b>		
1000W	800W	700W

Note: Each side removed reduces plate size by 3/8".

### Slide Dimmer 3-Way Wiring Diagram

