



## CATV-Cable TV / HDTV-High Definition TV / MATV-Master Antenna / Satellite-Digital & Broadband Video

Part#	Description	Rating	Application Solution
<b>Bare Copper (BC) center conductor for CATV, HDTV &amp; MATV applications</b>			
920414	RG6 18BC QUAD 60/40% AL Braid	CM/CL3	CATV - Best shielding
92049	RG6 18BC 60% AL Braid	CM/CL3	CATV - Good shielding
<b>Copper Clad Steel (CCS) center conductor for best strength &amp; durability</b>			
92041	RG6 18CCS QUAD 60/40% AL Braid	CM/CL3	CATV - Best RG6 for high & low frequency
92042	RG6 18CCS QUAD	CL2	CATV - Economical quad-nominal braid
92003	RG6 18CCS 60% AL Braid	CM/CL3	CATV - Good shielding
92008	RG6 18CCS	CL2	CATV - Economical RG6-nominal braid
920036	RG6 18CCS 60% AL Braid	CMR	CATV - Riser rated
992479	RG6 18CCS 60% AL Braid		CATV - Direct burial
92001	RG6 18CCS 40% AL Braid	CM/CL3	CATV - Most economical-minimal shielding

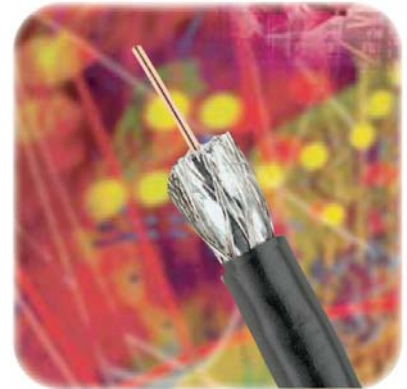

## CCTV - Closed Circuit TV

Part#	Description	Rating	Application Solution
92074	RG59 20BC 95%BC	CM/CL3	CCTV - Most common
99969	RG59 20BC 95%BC	CMP/CL3P	CCTV - Plenum rated
192115	RG59 20BC 95%BC		CCTV - Direct burial
92045	RG6 18BC 95%BC	CL2	CCTV - Longer runs
192061	RG6 18BC 95%BC		CCTV - Direct burial for longer runs

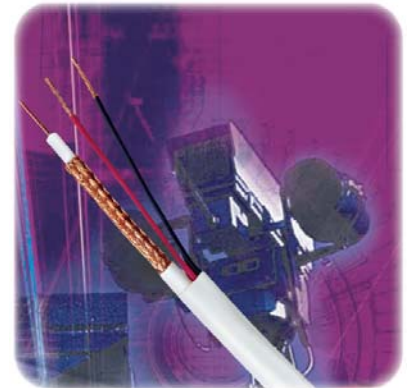


## Mini RG59 Precision Video Coax

Part#	Description	Rating	Application Solution
99401	(1) Mini Coax 23BC Foil+ 95%TC	CM/CL3	CATV & CCTV
99403	(3) Mini Coax 23BC Foil+ 95%TC	CM	CATV & CCTV
99405	(5) Mini Coax 23BC Foil+ 95%TC	CM	CATV & CCTV

## CCTV - Siamese Combo Coax Cables

Part#	Description	Rating	Application Solution
993253	RG59 20BC 95%BC + 18/2 Str BC	CM/CL3	CCTV (video & power)
993256	RG59 20BC 95%BC + 18/2 Str BC	CMP/CL3P	CCTV (video & power) Plenum Rated
993267	RG6 18BC 95%BC + 18/2 Str BC	CM	CCTV (video & power) for longer runs
993265	RG6 18BC 95%BC + 18/2 Str BC	CMP	CCTV (video & power) Plenum Rated

\* Other combo cables also available... see the CCI Home Structured Cable Solutions for more information

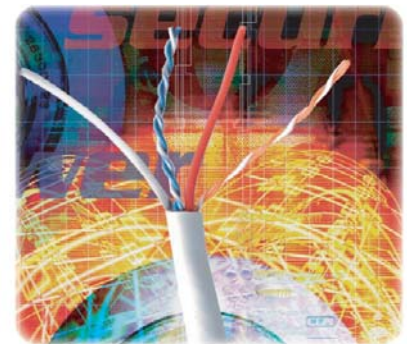

## Power/ Watch™ Combination CCTV over UTP Cables

Part#	Description	Rating	Application Solution
97194	(1) 24/2 pair solid BC (Cat 5E twist)	CL2R	CCTV-Riser Rated
	(1) 16/2 stranded BC (19/0.0117) power cables		
97195	(1) 24/2 pair solid BC (Cat 5E twist)	CL2P	CCTV-Plenum Rated
	(1) 16/2 stranded BC (19/0.0117) power cables		