



# ELLIOTT ELECTRIC SUPPLY

We Deliver...Lower Cost, Quality Products, & Personal Service

3804 South Street  
75964-7263, TX Nacogdoches  
Phone: 936-569-7941  
Fax: 936-560-4685



## 960 8.5" Electrical Locknut Plier

*Channellock, Inc.*

Catalog Number	960
Manufacturer	Channellock, Inc.
Description	Lock Nut Pliers, Spring Loaded; 8.5 Inch Overall Length; 2.38 Inch Jaw Length; 0.92 Inch Jaw Width; Weight 0.21 LB; Joint Thickness 0.38 Inch
Weight per unit	0.3400 (lbs/each)
Product Category	Pliers, Wrenches, Saw, Pouches

### Features

Jaw Length	2.38 INCH
Jaw Width	0.92 INCH

### Dimensions and Weight

Overall Length	8.5 INCH
----------------	----------

### Descriptions

Additional Information	WEIGHT 0.21 LB; JOINT THICKNESS 0.38 INCH
Commodity Description	PLRS,WRNCH,DRV,SAW,POUCH,TOOL BOX
Description	8.5" ELECTRICAL LOCKNUT PLIER
Long Description	LOCK NUT PLIERS, SPRING LOADED; 8.5 INCH OVERALL LENGTH; 2.38 INCH JAW LENGTH; 0.92 INCH JAW WIDTH; WEIGHT 0.21 LB; JOINT THICKNESS 0.38 INCH
Product Type	Locknut Plier

### Manufacturer Information

Brand	Channellock, Inc.
-------	-------------------


### Taxonomies, Classifications, and Categories

Category Description	HAND TOOLS
Type	SPRING LOADED

### Packaging

Carton	1
Package	5
Weight Per each	0.34

# SPECIAL PURPOSE PLIERS

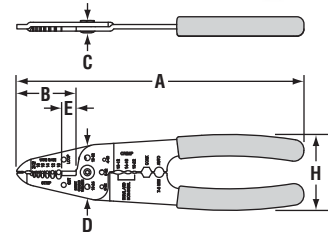


PLIER	A OVERALL LENGTH		B JAW LENGTH		C JOINT THICKNESS		D JOINT WIDTH		E CUTTING EDGE		H HANDLE SPAN		WEIGHT	
	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	pounds	grams
908	8.25	209.55	1.68	42.67	0.34	8.64	1.48	37.59	0.49	12.45	2.18	55.37	0.48	217.72

## Features

- Strips wire with no damage to conductor.
- Crimps insulated and non-insulated wire.
- Dénude le fil sans endommager le conducteur.
- Serit les fils isolés et non-isolés.
- Desforra alambres sin daño alguno al conductor.
- Poncha alambres aisladas y no aisladas.

## Features

- Retaining ring pliers
- Converts from internal to external rings with simple switch of the red tab.
- 929 – External: 1 1/2" to 4", Internal: 1 1/16" to 4" Includes tips: .090, .108, .120 15° and .090, .108, .120 90°
- 927 – External: 1/4" to 2", Internal: 3/8" to 2" Includes tips: .036, .047, .070 straight and .036, .047 90°
- 926 – External: 1/8" to 1", Internal: 1/4" to 1" Includes tips: .023, .036, .047 straight and .036, .047 90°
- Pince pour anneau élastique
- Convertissable de circlips intérieur à circlips extérieur en déplaçant simplement le bouton rouge.
- 929 – Circlips extérieurs : 38.1 à 101.6 mm, intérieurs : 46.04 à 101.6 mm. Comprend les embouts suivants : 2.29, 2.74, 3.05 mm coudés à 15° et 2.29, 2.74, 3.05 mm coudés à 90°
- 927 – Circlips extérieurs : 6.35 à 50.80 mm, intérieurs : 9.53 à 50.80 mm. Comprend les embouts suivants : 0.91, 1.19, 1.78 mm droits et 0.91, 1.19 mm coudés à 90°
- 926 – Circlips extérieurs : 3.18 à 25.40 mm, intérieurs : 6.35 à 25.40 mm. Comprend les embouts suivants : 0.58, 0.91, 1.19 mm droits et 0.91, 1.19 mm coudés à 90°
- Pinza para anillo de retención
- Convierte para usarse en anillos internos o externos con un simple cambio de la lengüeta roja.
- 929: Externos: 38.1 a 101.6 mm; Internos: 46.04 a 101.6 mm. Incluye puntas de 2.29, 2.74 y 3.05 mm de 15° y 2.29, 2.74 y 3.05 mm de 90°.
- 927: Externos: 6.35 a 50.80 mm; Internos: 9.53 a 50.80 mm. Incluye puntas de 0.91, 1.19 y 1.78 mm rectas y 0.91 y 1.19 mm de 90°.
- 926: Externos: 3.18 a 25.40 mm; Internos: 6.35 a 25.40 mm. Incluye puntas de 0.58, 0.91 y 1.19 mm rectas y 0.91 y 1.19 mm de 90°.

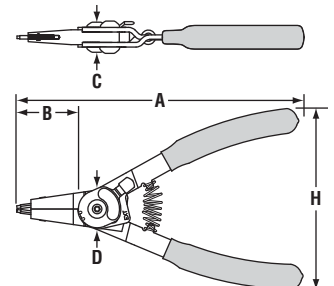


PLIER	A OVERALL LENGTH		B JAW LENGTH		C JOINT THICKNESS		D JOINT WIDTH		E CUTTING EDGE		H HANDLE SPAN		WEIGHT	
	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	pounds	grams
929	10.00	254.00	1.38	35.05	1.00	25.40	1.25	31.75	N/A	N/A	4.75	120.65	1.06	480.81
927	8.00	203.20	1.60	40.64	0.97	24.64	1.71	43.43	N/A	N/A	4.85	123.19	0.50	226.80
926	6.25	158.75	1.31	33.27	0.87	22.10	1.12	28.45	N/A	N/A	3.29	83.57	0.32	145.15

U.S. Patent No. 7,194,936 B2

## Features

- Locknut plier
- Fits most popular UL locknut sizes. (metal, PVC, plastic)
- Thin profile for confined spaces.
- Pincas à contre-écrou
- Convient aux tailles d'écrou d'arrêt les plus communes (métal, PVC, plastique).
- Profil effilé pour espaces confinés.
- Alicata para contratuercas
- Se ajusta a los tamaños más populares de contratuercas (metal, PVC, plástico).
- Perfil delgado para espacios estrechos.

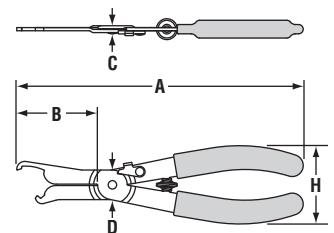

PLIER	A OVERALL LENGTH		B JAW LENGTH		C JOINT THICKNESS		D JOINT WIDTH		E CUTTING EDGE		H HANDLE SPAN		WEIGHT	
	in	mm	in	mm	in	mm	in	mm	in	mm	in	mm	pounds	grams
960	8.50	215.90	2.38	60.45	0.21	5.33	0.92	23.37	N/A	N/A	2.54	64.52	0.48	217.72

U.S. Patent No. 7,197,967