


## Insulating Bushings - Knockout

### Images

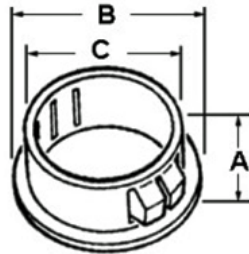

### Application

Converts metallic box rough edged knockout holes to smooth insulated holes for protection of electrical and telecommunications cable. Rated 105 Degrees C.

### Product Information

Material: Plastic  
Finish: Natural

### Certifications & Codes:

CSA File Number: LR24719  
NEMA Standard: FB-1  
UL Standard: UL-514B  
UNSPSC: 39121312

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-15/16

Dimension B in Inches: 2-5/8

Dimension C in Inches: 2-1/2

**Catalog ID:** 9796

**UPC Number:** 781747007964

**Description:** Bushing, Insulating, Plastic Rated 105 Degrees C, 2.500 Inch Hole Dia.

**Application:** Converts metallic box rough edged knockout holes to smooth insulated holes for protection of electrical and telecommunications cable. Rated 105 Degrees C.

**Trade Size:** 2"


**Country of Manufacture:** USA

**Std Pkg Qty:** 100

**Unit Qty:** 20

## Insulating Bushings - Knockout

### Images

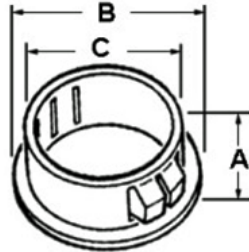

### Application

Converts metallic box rough edged knockout holes to smooth insulated holes for protection of electrical and telecommunications cable. Rated 105 Degrees C.

### Product Information

Material: Plastic  
Finish: Natural

### Certifications & Codes:

CSA File Number:	LR24719
NEMA Standard:	FB-1
UL Standard:	UL-514B
UNSPSC:	39121312

[Download Photo Image](#)   [Download Dimensional Image](#)  
Dimension A in Inches: 1-15/16  
Dimension B in Inches: 2-5/8  
Dimension C in Inches: 2-1/2

**Catalog ID:** 9796

**UPC Number:** 781747007964

**Description:** Bushing, Insulating, Plastic Rated 105 Degrees C, 2.500 Inch Hole Dia.

**Application:** Converts metallic box rough edged knockout holes to smooth insulated holes for protection of electrical and telecommunications cable. Rated 105 Degrees C.

**Trade Size:** 2"

**Country of Manufacture:** USA

**Std Pkg Qty:** 100

**Unit Qty:** 20