


## Insulating Bushings - Knockout

### Images

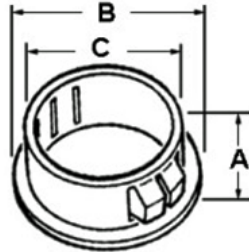

### Application

Converts metallic box rough edged knockout holes to smooth insulated holes for protection of electrical and telecommunications cable. Rated 105 Degrees C.

### Product Information

Material: Plastic  
Finish: Natural

### Certifications & Codes:

CSA File Number: LR24719  
UNSPSC: 39121312

[Download Photo Image](#)   [Download Dimensional Image](#)

Dimension A in Inches: 11/16  
Dimension B in Inches: 3-13/64  
Dimension C in Inches: 2-31/32

**Catalog ID:** 9797

**UPC Number:** 78174700797

**Description:** Bushing, Insulating, Plastic Rated 105 Degrees C, 3.000 Inch Hole Dia.

**Application:** Converts metallic box rough edged knockout holes to smooth insulated holes for protection of electrical and telecommunications cable. Rated 105 Degrees C.

**Trade Size:** 2-1/2"

**Country of Manufacture:** USA

**Std Pkg Qty:** 100

**Unit Qty:** 20