

### Dust tight grips

#### Product description

Wide range - straight male NPT



TCI254

#### Features & applications

- Provides secure cable termination and prevents cable pullout
- Absorbs longitudinal stresses placed on the point of termination caused by pulling or bending the cable
- Supplied with locknut, nylon insulated bushing and neoprene gasket to provide a dirt and dust free seal
- Constructed with steel mesh and aluminum threaded body adding to safety by extending cable life
- Wide range, single weave mesh construction
- Recommended for indoor use in wiring of enclosures, power boxes, machine tools and power centers

#### Dust tight grips




| Cord diameter            | NPT             | Non-insulated catalog no. |   | Insulated catalog no. |   |
|--------------------------|-----------------|---------------------------|---|-----------------------|---|
| 0.22-0.32" (5.6-8.1mm)   | 1/2" (12.7mm)   | □ TC124*                  | • | □ TCI124              | • |
| 0.30-0.43" (7.6-10.9mm)  | 1/2" (12.7mm)   | □ TC132*                  | • | □ TCI132              | • |
| 0.40-0.54" (10.1-13.7mm) | 1/2" (12.7mm)   | □ TC143*                  | • | □ TCI143              | • |
| 0.52-0.73" (13.2-18.5mm) | 3/4" (19.0mm)   | □ TC254*                  | • | □ TCI254              | • |
| 0.70-0.97" (17.8-24.6mm) | 1" (25.4mm)     | □ TC373*                  | • | □ TCI373              | • |
| 0.94-1.25" (23.8-31.8mm) | 1-1/4" (31.8mm) | □ TC497*                  | • | □ TCI497              | • |
| 1.20-1.50" (30.5-38.1mm) | 1-1/2" (38.1mm) | —                         |   | □ TCI5125             | • |
| 1.40-1.75" (38.1-44.5mm) | 2" (50.8mm)     | —                         |   | □ TCI6150             | • |
| 1.62-2.00" (41.1-50.8mm) | 2-1/2" (63.5mm) | —                         |   | □ TCI7170             | • |
| 2.00-2.45" (50.8-62.2mm) | 2-1/2" (63.5mm) | —                         |   | □ TCI7200             | • |

\* Not UL Listed

### I-grips

#### Product description

Wiring device

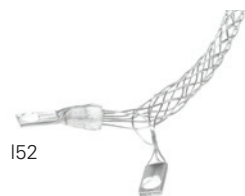

I52

#### Features & applications

- Provides heavy duty strain relief and controls the bending arc on 2-wire, 3-wire, 4-wire and 5-wire Arrow Hart safety grip plug and connector cord assemblies
- Single weave wire mesh made of high strength galvanized steel
- Fast, easy installation. Eye tabs fit under the nylon cord clamps, screws slide through the tabs and secure the grip in place
- Ideal for portable equipment in industrial and commercial applications

#### I-grips



| Cord diameter            | Mesh length      | Catalog no. |   |
|--------------------------|------------------|-------------|---|
| 0.30-0.43" (7.6-10.9mm)  | 4.75" (120.6mm)  | □ I30       | • |
| 0.40-0.56" (10.1-14.2mm) | 6.00" (152.4mm)  | □ I40       | • |
| 0.52-0.73" (13.2-18.5mm) | 7.00" (177.8mm)  | □ I52       | • |
| 0.70-0.85" (17.8-21.6mm) | 8.50" (215.9mm)  | □ I70       | • |
| 0.82-1.00" (20.8-25.4mm) | 8.50" (215.9mm)  | □ I82       | • |
| 0.94-1.25" (23.9-31.8mm) | 10.50" (266.7mm) | □ I94       | • |

Compliances, specifications and availability are subject to change without notice.

Indicates NAFTA compliant - Page Q-30