


EZ Lock - Connector - Steel

Images

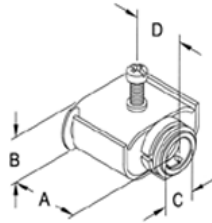

Application

Recommended cable types used to connect AC/MC/MCI-A, Diameter for 14/2 (.43" 0 min) to 10/3 (.62" 0 max)

Product Information

Material: Steel
Finish: Zinc Electro-Plate

Certifications & Codes:

CSA File Number:	LR39354
Federal Specification Number:	A-A-50552
NEMA Standard:	FB-1
UL File Number:	E20534
UL Standard:	UL-514B
UNSPSC:	39121419

[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: 1-1/2
Dimension B in Inches: 11/16
Dimension C in Inches: 9/16
Dimension D in Inches: 13/16

Catalog ID: AMC-52

UPC Number: 78174720580

Description: Connector, E-Z Lock, Steel, .560 Inch Throat Opening

Application: Recommended cable types used to connect AC/MC/MCI-A, Diameter for 14/2 (.43" 0 min) to 10/3 (.62" 0 max)

Trade Size: 3/8"

Std Pkg Qty: 250

Unit Qty: 25