

POPULAR COMBINATIONS

Sentry | TRADITIONAL STYLE



A Oiled Bronze Sentry with 56" Custom Carved Classic Ebony Blades

Model-Finish **SN52OB**
Blade-Finish **B556C-SB4**
Light-Finish **Not Shown**

B Antique White Sentry with 52" Standard Antique White Blades

Model-Finish **SN52AW**
Blade-Finish **B552S-AW**
Light-Finish **Not Shown**


C Detail of Uplight

AVAILABLE FINISHES

AW	Antique White
BN	Brushed Satin Nickel
OB	Oiled Bronze

BLADE OPTIONS

Type 1 Blades (see pages 222-225)	Type 2 Blades (see pages 226-230)
--------------------------------------	--------------------------------------


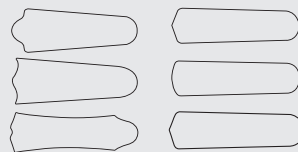


LIGHT KIT OPTIONS

Bowl Light Kits (see pages 242-246)	Complete Light Kits (see pages 246-248)	Customize Your Own (see pages 249-252)
--	--	---



  REMOTES



TCS Conversion Kit:

A Replacement Hub converts a Fan to a TCS or TCS-PLUS system. Both systems adjust Fan Speed, Fan Direction and light intensity. See Ordering Guide below for the system that's right for you.



TCS Remote Control:

- Fan and Light Control
- 1.5 Amp
- White Hand-Held Remote with Wall Mount
- 300 Watt Full Range Light Dimmer
- 3 Fan Speeds and Reverse
- Replacement Hub Included
- Additional Hand-Held Remotes Available
- See Ordering Guide for Series Availability
- 1-12V Battery Included

Important: One Fan Per Remote Control.



TCS-PLUS Wall Control:

- Fan and Light Control
- 2-Wire Installation for Power On/Off to Junction Box.
Note: Two Wires Only Interrupt 120VAC to Junction Box, Fan Functions are Battery Powered.
- 1.5 Amp
- 12V Battery (Included)
- White Decorative Face Plates (Included)
- 300 Watt Full Range Light Dimmer
- 3 Fan Speeds and Reverse
- See Ordering Guide for Series Availability
- Replacement Hub Included
- White, Almond and Brown Decorative Insert (Included) *Important: One Fan Per Wall Control.*

TCS Remote Control and TCS-PLUS Wall Control Sets:

Interchangeable and programmable to operate on the same frequency. Thus, you may add a Remote Control Unit (TCS) to your Wall Control (TCS-PLUS) or a Wall Control to your Remote Control. Just order TCS-REMOTE for a Handset or TCS-WALL for a Wall Control.


Model	Series	TCS Remote Control	TCS-Plus Wall Control
AT52	American Tradition	AT-TCS-(Finish)	AT-TCSPLUS-(Finish)
CP52	Chaparral	CP-TCS-(Finish)	CP-TCSPLUS-(Finish)
CT52	Constantina	CT-TCS-(Finish)	CT-TCSPLUS-(Finish)
CV52	Cordova	CV-TCS-(Finish)	CV-TCSPLUS-(Finish)
CXL52	CXL	CXL-TCS-(Finish)	CXL-TCSPLUS-(Finish)
FI52	Fiori	FI-TCS-(Finish)	FI-TCSPLUS-(Finish)
K52	Kona Bay	K52-TCS-(Finish)	K52-TCSPLUS-(Finish)
ME52	Metro	CT-TCS-(Finish)	CT-TCSPLUS-(Finish)
MI52	Mia	MI-TCS-(Finish)	MI-TCSPLUS-(Finish)
OA52	Ophelia	OA-TCS-(Finish)	OA-TCSPLUS-(Finish)
OM52	Omni	OM-TCS-(Finish)	OM-TCSPLUS-(Finish)
P252	Presidential II	P2-TCS-(Finish)	P2-TCSPLUS-(Finish)
RT52/RT68	Riata	RT-TCS-(Finish)	RT-TCSPLUS-(Finish)
SN52	Sentry	AT-TCS-(Finish)	AT-TCSPLUS-(Finish)
TO52	Toscana	TO-TCS-(Finish)	TO-TCSPLUS-(Finish)
WD52	Woodward	WD-TCS-(Finish)	WD-TCSPLUS-(Finish)
ZE56	Zena	ZE-TCS-(Finish)	ZE-TCSPLUS-(Finish)

Ceiling Fan


FINISH OPTIONS



 
AB
Antique Brass



ABZ
Aged Bronze
Brushed

 

AG
Aged Bronze
Textured

 


AGV
Aged Galvanized



AGVM
Aged Bronze/
Vintage Madera



 AO
Athenian Obol



AW
Antique White



 
AWD
Antique White/
Distressed




BA
Brushed Aluminum




BCW
Biscay Walnut




BN
Brushed Satin Nickel

 

BNK
Brushed Polished Nickel

 


BR
Brown

 

BU
Burnt Sienna



 
CH
Chrome



DCVM
Dark Coffee/
Vintage Madera



 ESP
Espresso




FB
Flat Black




FW
French White



 
GV
Galvanized Steel




LB
Legacy Brass

 


OB
Oiled Bronze

 

MWW
Matte White

 

OBG
Oiled Bronze/ Gilded

 


OBMA
Oiled Bronze/ Mahogany



PB
Polished Brass



 PLN
Polished Nickel



PR
Peruvian Bronze



PT
Pewter



RI
Rustic Iron



RT
Rust



SC
Sedona Clay



SBZ
Spanish Bronze



SS
Stainless Steel



 
TI
Titanium



TS
Tarnished Silver



TW
Textured White



W
White



WP
Weathered Pine