


B6RIC

6" Universal IC Remodel Housing

LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30



DESIGNED FOR 2" X 8" JOIST CONSTRUCTION

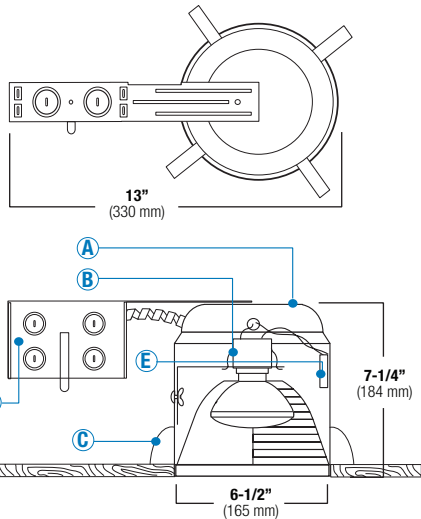

ITEM SELECTOR: (Please check the boxes below for the option desired)

| TYPE | AIR-SHUT | OPTION | TRIM TYPE | | | | | | | BAFFLE | REFLECTOR | TRIM/RING | GLASS | |
|-------|-----------------------------|--|--------------------------------|--------------------------------|--------------------------------|--------------------------------|-------------------------------|-------------------------------|-----------------------------|------------------------------|-----------------------------|------------------------------------|-------|--|
| B6RIC | <input type="checkbox"/> AT | <input type="checkbox"/> (W) With quick connects | <input type="checkbox"/> B630 | <input type="checkbox"/> B609 | <input type="checkbox"/> B606L | <input type="checkbox"/> B676 | <input type="checkbox"/> B651 | <input type="checkbox"/> B688 | <input type="checkbox"/> W | <input type="checkbox"/> CL | <input type="checkbox"/> WH | <input type="checkbox"/> Green | | |
| | | | <input type="checkbox"/> B620 | <input type="checkbox"/> B619 | <input type="checkbox"/> B635 | <input type="checkbox"/> B612 | <input type="checkbox"/> B611 | <input type="checkbox"/> B685 | <input type="checkbox"/> P | <input type="checkbox"/> RG | <input type="checkbox"/> BK | <input type="checkbox"/> Yellow | | |
| | | | <input type="checkbox"/> B631 | <input type="checkbox"/> B646 | <input type="checkbox"/> B636 | <input type="checkbox"/> B645 | <input type="checkbox"/> B647 | <input type="checkbox"/> B696 | <input type="checkbox"/> SN | <input type="checkbox"/> W | <input type="checkbox"/> SN | <input type="checkbox"/> Pink | | |
| | | | <input type="checkbox"/> AF637 | <input type="checkbox"/> B616 | <input type="checkbox"/> B642 | <input type="checkbox"/> B648 | <input type="checkbox"/> B644 | <input type="checkbox"/> B689 | <input type="checkbox"/> CP | <input type="checkbox"/> MB | <input type="checkbox"/> CP | <input type="checkbox"/> Brown | | |
| | | | <input type="checkbox"/> AF631 | <input type="checkbox"/> B663 | <input type="checkbox"/> B641 | <input type="checkbox"/> B652 | <input type="checkbox"/> B650 | <input type="checkbox"/> B680 | <input type="checkbox"/> BZ | <input type="checkbox"/> BZ | <input type="checkbox"/> CH | <input type="checkbox"/> Navy Blue | | |
| | | | <input type="checkbox"/> AF639 | <input type="checkbox"/> B673 | <input type="checkbox"/> B656 | <input type="checkbox"/> B603 | <input type="checkbox"/> B622 | | | <input type="checkbox"/> CP | <input type="checkbox"/> PB | <input type="checkbox"/> Orange | | |
| | | | <input type="checkbox"/> AF640 | <input type="checkbox"/> B683 | <input type="checkbox"/> B657 | <input type="checkbox"/> B615 | <input type="checkbox"/> B625 | | | <input type="checkbox"/> SN | <input type="checkbox"/> BZ | <input type="checkbox"/> Blue | | |
| | | | <input type="checkbox"/> AF632 | <input type="checkbox"/> B601 | <input type="checkbox"/> B637 | <input type="checkbox"/> B633 | <input type="checkbox"/> B624 | | | <input type="checkbox"/> SHZ | | <input type="checkbox"/> White | | |
| | | | <input type="checkbox"/> B610 | <input type="checkbox"/> B601L | <input type="checkbox"/> B643 | <input type="checkbox"/> B649 | <input type="checkbox"/> B681 | | | | | <input type="checkbox"/> Red | | |
| | | | <input type="checkbox"/> B607 | <input type="checkbox"/> B605 | <input type="checkbox"/> B658 | <input type="checkbox"/> AF633 | <input type="checkbox"/> B687 | | | | | | | |
| | | | <input type="checkbox"/> B608 | <input type="checkbox"/> B605L | <input type="checkbox"/> B659 | <input type="checkbox"/> B225 | <input type="checkbox"/> B682 | | | | | | | |
| | | | <input type="checkbox"/> B602 | <input type="checkbox"/> B606 | <input type="checkbox"/> B675 | <input type="checkbox"/> B653 | <input type="checkbox"/> B693 | | | | | | | |
| | | | | | | | | | | | | | | |
| | | | | | | | | | | | | | | |

Specifications:

B6RIC

AIR-SHUT - OPTION - TRIM TYPE - BAFFLE - REFLECTOR - TRIM/RING - GLASS

Sample of Catalog Number: B6RIC-AT-W-B630-W-WH

*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.



Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: ELITE LIGHTING-SPEC-06-29-2011

Catalog Number:

Project Name:

Type:

Note:



DESCRIPTION

Thermally protected, IC rated specification grade remodel recessed housing. For remodeling installations where housing will be in direct contact with insulation. For fast and easy installation in existing plaster or mechanical ceilings from 1/2" to 1-3/8" thick. Four remodel clips are easily retractable for fixture removal if necessary. Junction box is provided with eight 1/2" KOs and four Romex knockouts with strain relief. Accommodates up to 75W PAR30, BR30, and A19 lamps.

SPECIFICATION


A. HOUSING - Die-formed, all aluminum construction for maximum heat dissipation and rust protection.

B. SOCKET - Medium base screw shell porcelain socket preinstalled on adjustable mounting bracket is designed to allow usage of different lamp types, as well as proper and consistent lamp positioning.

C. INSTALLATION - Four preinstalled spring clips which secure the housing firmly into ceiling to accommodate different ceiling thicknesses from 1/2" to 1-3/8".

D. JUNCTION BOX - UL listed for through-branch circuit wiring, provided with eight 1/2" KOs and four Romex knockouts with strain relief.

E. THERMAL PROTECTION - Standard thermal protection device guards against improper installation, overlamping and misuse of insulation material.

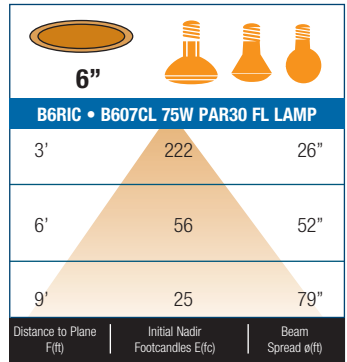

BEAM DIA. MEASURED AT 50% OF NADIR F.C.

FEATURES

- Thermally Protected remodel IC housing.
- Dependable, favorable design and effortless installation.
- Unit slips through 6-1/2" ceiling opening.
- Four preinstalled spring clips which secure the housing firmly into ceiling to accommodate different ceiling thickness from 1/2" to 1-3/8".
- Can be installed from below the ceiling.
- 7-1/4" height allows use in 2" x 8" joist construction.
- Wire through junction box.
- Adjustable socket bracket.
- Preinstalled socket cap provides electrical contact protection against dust, paint and over spray.

OPTIONS

AIR-SHUT

- Gasket to prevent air flow from heated or air conditioned spaces.
- Meets all national air flow requirements.

| BAFFLE | REFLECTOR | TRIM/RING |
|-----------------|-----------------|-----------------|
| W White | CL Chrome | WH White |
| P Black | RG Gold | BK Black |
| SN Satin Nickel | W White | SN Satin Nickel |
| CP Copper | MB Black | CP Copper |
| BZ Bronze | BZ Bronze | CH Chrome |
| | CP Copper | PB Polish Brass |
| | SN Satin Nickel | BZ Bronze |
| | SHZ Satin Haze | |

6" Incandescent Trims

(LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


elite LIGHTING

B630CP-CP
METAL STEPPED BAFFLE R30/PAR30



BAFFLE FINISH:
W, P, SN, CP, BZ


TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

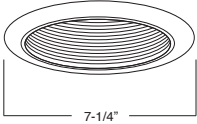


B620-ORANGE
GLASS TRIM



GLASS FINISH:
GREEN, YELLOW,
PINK, BROWN, NAVY
BLUE, ORANGE,
WHITE, RED

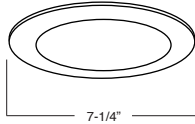


 B631P-WH
R30 PREMIUM PHENOLIC BAFFLE / METAL RING



BAFFLE FINISH:
W, P


TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

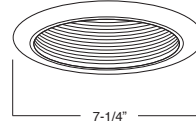

AF637W-WH
SELF FLANGE AIR-SHUT BAFFLE




AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, P-BK,
SN-SN, CP-CP, BZ-BZ

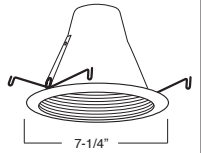

AF631W-WH
SELF FLANGE AIR-SHUT BAFFLE



AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, P-BK,
SN-SN, CP-CP, BZ-BZ

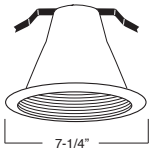


AF639W-WH
SELF FLANGE AIR-SHUT BAFFLE



AVAILABLE COLOR COMBINATIONS:
W-WH


MATT WHITE FINISH

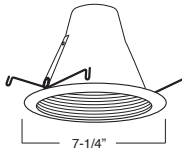

AF640W-WH
DEEP SELF FLANGE AIR-SHUT BAFFLE




AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, SN-SN,
CP-CP, BZ-BZ

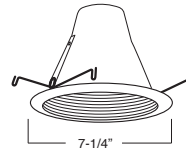

AF632RG-WH
AIR-SHUT REFLECTOR



AVAILABLE COLOR COMBINATIONS:
CL-WH, CL-CH,
RG-WH, W-WH,
MB-WH, CP-CP, SN-SN

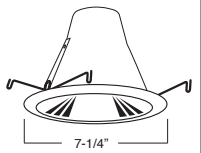


B610P-RG-WH
CONE REFLECTOR/BAFFLE TRIM



BAFFLE FINISH:
W, P

REFLECTOR FINISH:
CL, RG

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

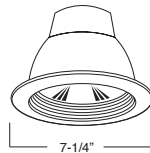

B607CP-WH
REFLECTOR R/PAR30



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN,
BZ, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ




B608CL-WH
CONE REFLECTOR A19



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN,
BZ, SHZ


TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

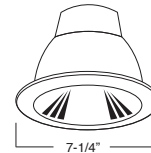

B602SN
EYEBALL



TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

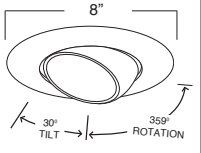


B609W-WH
REGRESSED EYEBALL WITH BAFFLE



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

EYEBALL FINISH:
WH, BK, SN, CP, CH, PB, BZ

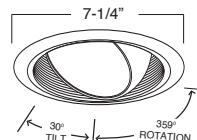


B619RG-PB
REGRESSED EYEBALL WITH REFLECTOR




REFLECTOR FINISH:
CL, RG, W, MB, CP, SN

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

EYEBALL FINISH:
WH, BK, SN, CP, CH, PB, BZ

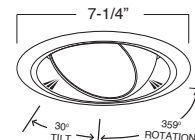


B646P-WH
EYEBALL WITH BAFFLE

 

BAFFLE FINISH:
W, P

TRIM/RING FINISH:
WH

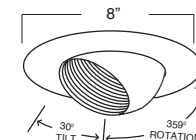


B616W-WH
PAR20 REGRESSED EYEBALL W/ BAFFLE



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

EYEBALL FINISH:
WH, BK, SN, CP, CH, PB, BZ

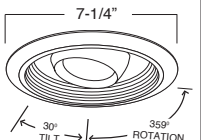

elite LIGHTING

Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011

6" Incandescent Trims

(LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

 
Project Name:

Type:


Note:

elite LIGHTING


B663PB
PAR30 GIMBAL RING



TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

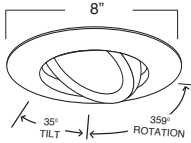


B673P-WH
PAR30 BAFFLE W/ GIMBAL RING

 


BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

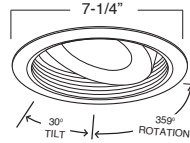


 B683CL-WH
PAR30 REFLECTOR W/ GIMBAL RING



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

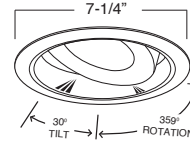


B601CP
METAL ALBALITE LENS



FOR
WET
LOCATION

LENS:
ALBALITE

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

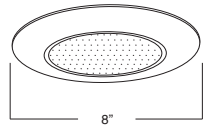


B601L
PLASTIC ALBALITE LENS



FOR
WET
LOCATION

LENS:
ALBALITE

TRIM/RING FINISH:
WHITE PLASTIC

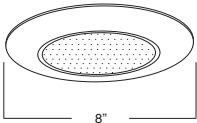


B605PB
METAL FRESNEL LENS



FOR
WET
LOCATION

LENS:
FRESNEL

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

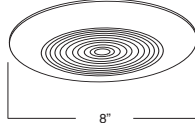


B605L
PLASTIC FRESNEL LENS



FOR
WET
LOCATION

LENS:
FRESNEL

TRIM/RING FINISH:
WHITE PLASTIC

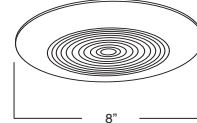


B606CP
METAL DROP OPAL LENS



FOR
WET
LOCATION

LENS:
DROP OPAL

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

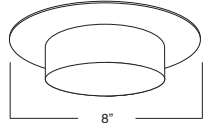


B606L
PLASTIC DROP OPAL LENS



FOR
WET
LOCATION

LENS:
DROP OPAL

TRIM/RING FINISH:
WHITE PLASTIC

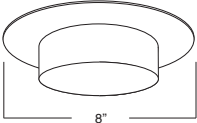


B635P-WH
BAFFLE W/ ALBALITE LENS



FOR
WET
LOCATION

BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

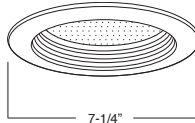


B636W-WH
BAFFLE W/ FRESNEL LENS



FOR
WET
LOCATION

BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

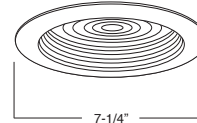


B642CL-WH
REFLECTOR W/ FRESNEL LENS



FOR
WET
LOCATION

REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

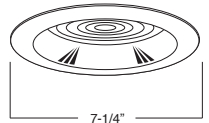


B641RG-WH
REFLECTOR W/ ALBALITE LENS



FOR
WET
LOCATION

REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

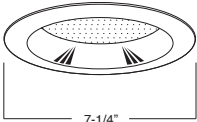


B656W-WH
BAFFLE W/ FROSTED DOME SHOWER LENS



FOR
WET
LOCATION

BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

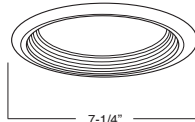


B657CL-WH
REFLECTOR W/ FROSTED DOME SHOWER LENS



FOR
WET
LOCATION

REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

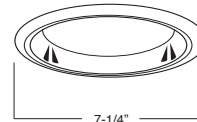


B637W-WH
BAFFLE W/ DROP OPAL LENS



FOR
WET
LOCATION

BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

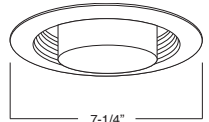

elite LIGHTING

Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011

6" Incandescent Trims

(LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


elite LIGHTING

B643RG-WH
REFLECTOR W/ DROP OPAL LENS



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

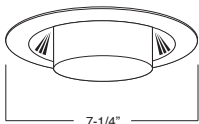


B658CL-WH
REFLECTOR W/ PRISMATIC LENS



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

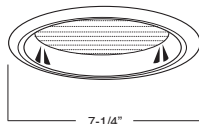


B659CL-WH
REFLECTOR W/ FROSTED LENS



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

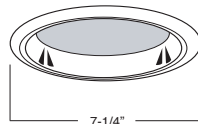


B675W-WH
BAFFLE W/ PRISMATIC LENS



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

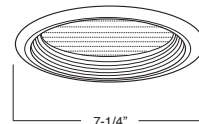


B676W-WH
BAFFLE W/ FROSTED LENS



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

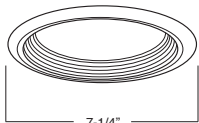


B612WH
SMOOTH FROST DOME SHOWER LENS



LENS:
FROSTED

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

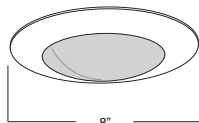


B645WH
DESIGNER POINT SHOWER LENS



LENS:
FROSTED/CLEAR

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

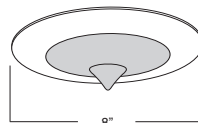


B648WH
DESIGNER CONE SHOWER LENS



LENS:
FROSTED

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

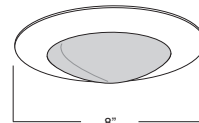


B652WH
SMOOTH FROST SHOWER LENS




LENS:
FROSTED


TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

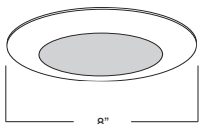

B603CP
R/PAR30 OPEN TRIM

 


TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

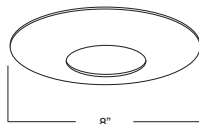

B615WH
DESIGNER PINHOLE




TRIM/RING FINISH:
WH, BK

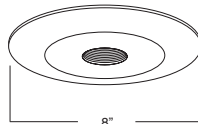

B633WH
R/PAR30 SPLAY TRIM



TRIM/RING FINISH:
WH, BK

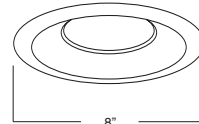


B649RG-WH
PAR20 REFLECTOR



REFLECTOR FINISH:
CL, RG, W, MB,
CP, SN

TRIM/RING FINISH:
WH, BK

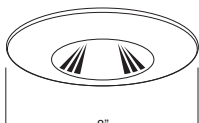

AF633CH
R/PAR30 OPEN TRIM



TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ




B225WH
OPEN TRIM STEPPED BAFFLE




BAFFLE FINISH:
W, P

TRIM/RING FINISH:
WH

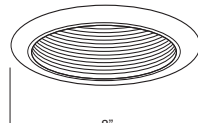


B653W-WH
BAFFLE WITH BAFFLE

 

BAFFLE FINISH:
W, P

TRIM/RING FINISH:
WH, BK, SN, CP,
CH, PB

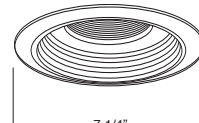

elite LIGHTING

Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011

6" Incandescent Trims

(LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

 
Project Name:

Type:

Note:


elite LIGHTING

**B651P-WH
PAR20 STEPPED BAFFLE**




BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK

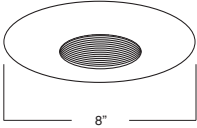


8"

 **B611W-WH
PAR30 BAFFLE WALL WASH**



AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, SN-SN, CP-CP, BZ-BZ

COVER FINISH:
WH, BK

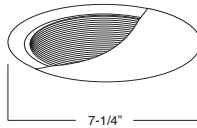


7-1/4"

**B647P-WH
DESIGNER BAFFLE WALL WASH PAR20**



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH

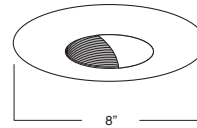


8"

**B644RG-WH
DESIGNER REFLECTOR WALL WASH PAR20**



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN

TRIM/RING FINISH:
WH

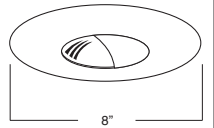


8"

**B650WH
DESIGNER WALL WASH**



TRIM/RING FINISH:
WH

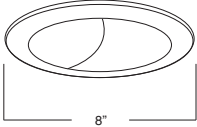

8"


**B622RG-WH
R/PAR30 WALL WASH REFLECTOR**



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN, SHZ

COVER FINISH:
WH

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

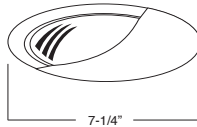

7-1/4"


**B625CL-WH
A-19 CONE REFLECTOR WALL WASH**



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN, SHZ

COVER FINISH:
WH

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

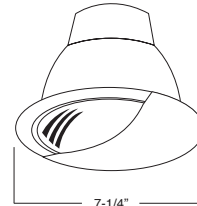

7-1/4"

**B624W-CL
CONE REFLECTOR BAFFLE WALL WASH**




BAFFLE FINISH:
W, P

REFLECTOR FINISH:
CL, RG


COVER FINISH:
WH

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

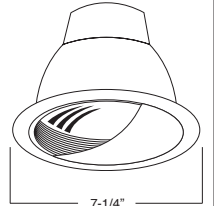


7-1/4"

 **B681CP-WH
SQUARE BAFFLE TRIM**



BAFFLE FINISH:
W, P, SN, CP, BZ

 TRIM/RING FINISH:
WH, BK, SN, CP




7-1/2"

**B687CP-WH
SQUARE REFLECTOR TRIM**



REFLECTOR FINISH:
CL, RG, W, MB, SN, CP

 TRIM/RING FINISH:
WH, BK, SN, CP




7-1/2"

**B682WH
SQUARE EYEBALL TRIM**



 TRIM/RING FINISH:
WH




7-1/2"

**B693WH
SQUARE PAR30 GIMBAL TRIM**



 TRIM/RING FINISH:
WH




7-1/2"

**B688WH
SQUARE ALBALITE SHOWER TRIM**



LENS:
WHITE

 TRIM/RING FINISH:
WH




7-1/2"

**B685WH
SQUARE FRESNEL SHOWER TRIM**



LENS:
CLEAR

 TRIM/RING FINISH:
WH




7-1/2"

**B696WH
SQUARE DROP OIPAL SHOWER TRIM**



LENS:
WHITE

 TRIM/RING FINISH:
WH




7-1/2"

**B689WH
SQUARE DESIGNER CONE SHOWER LENS**



LENS:
FROSTED

 TRIM/RING FINISH:
WH



7-1/2"

elite LIGHTING

Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011

6" Incandescent Trims

(LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:

elite LIGHTING


B680WH SQUARE DESIGNER POINT LENS



FOR
WET
LOCATION

LENS:
FROSTED/CLEAR

TRIM/RING FINISH:
WH

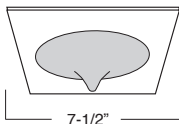

| BAFFLE | REFLECTOR | TRIM RING |
|------------------------|------------------------|------------------------|
| W White | CL Chrome | WH White |
| P Black | RG Gold | BK Black |
| SN Satin Nickel | W White | SN Satin Nickel |
| CP Copper | MB Black | CP Copper |
| BZ Bronze | CP Copper | CH Chrome |
| | SN Satin Nickel | PB Polish Brass |
| | | BZ Bronze |

**For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.*


B6RIC

6" Universal IC Remodel Housing

LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30



DESIGNED FOR 2" X 8" JOIST CONSTRUCTION

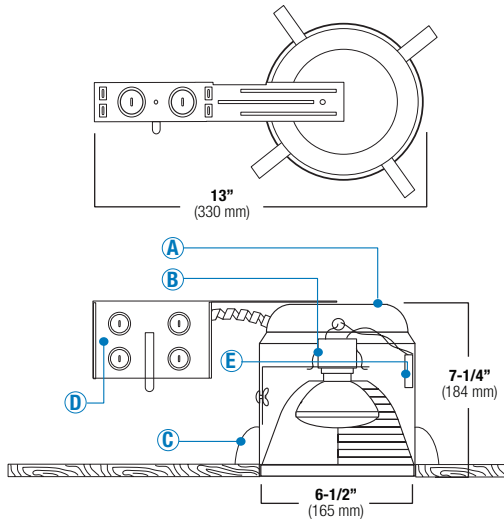

ITEM SELECTOR: (Please check the boxes below for the option desired)

| TYPE | AIR-SHUT | OPTION | TRIM TYPE | | | | | | | BAFFLE | REFLECTOR | TRIM/RING | GLASS | |
|-------|-----------------------------|--|--------------------------------|--------------------------------|--------------------------------|--------------------------------|-------------------------------|-------------------------------|------------------------------|-----------------------------|---------------------------------|------------------------------------|-------|--|
| B6RIC | <input type="checkbox"/> AT | <input type="checkbox"/> (W) With quick connects | <input type="checkbox"/> B630 | <input type="checkbox"/> B609 | <input type="checkbox"/> B606L | <input type="checkbox"/> B676 | <input type="checkbox"/> B651 | <input type="checkbox"/> B688 | <input type="checkbox"/> W | <input type="checkbox"/> CL | <input type="checkbox"/> WH | <input type="checkbox"/> Green | | |
| | | | <input type="checkbox"/> B620 | <input type="checkbox"/> B619 | <input type="checkbox"/> B635 | <input type="checkbox"/> B612 | <input type="checkbox"/> B611 | <input type="checkbox"/> B685 | <input type="checkbox"/> P | <input type="checkbox"/> RG | <input type="checkbox"/> BK | <input type="checkbox"/> Yellow | | |
| | | | <input type="checkbox"/> B631 | <input type="checkbox"/> B646 | <input type="checkbox"/> B636 | <input type="checkbox"/> B645 | <input type="checkbox"/> B647 | <input type="checkbox"/> B696 | <input type="checkbox"/> SN | <input type="checkbox"/> W | <input type="checkbox"/> SN | <input type="checkbox"/> Pink | | |
| | | | <input type="checkbox"/> AF637 | <input type="checkbox"/> B616 | <input type="checkbox"/> B642 | <input type="checkbox"/> B648 | <input type="checkbox"/> B644 | <input type="checkbox"/> B689 | <input type="checkbox"/> CP | <input type="checkbox"/> MB | <input type="checkbox"/> CP | <input type="checkbox"/> Brown | | |
| | | | <input type="checkbox"/> AF631 | <input type="checkbox"/> B663 | <input type="checkbox"/> B641 | <input type="checkbox"/> B652 | <input type="checkbox"/> B650 | <input type="checkbox"/> B680 | <input type="checkbox"/> BZ | <input type="checkbox"/> BZ | <input type="checkbox"/> CH | <input type="checkbox"/> Navy Blue | | |
| | | | <input type="checkbox"/> AF639 | <input type="checkbox"/> B673 | <input type="checkbox"/> B656 | <input type="checkbox"/> B603 | <input type="checkbox"/> B622 | | <input type="checkbox"/> CP | <input type="checkbox"/> PB | <input type="checkbox"/> Orange | | | |
| | | | <input type="checkbox"/> AF640 | <input type="checkbox"/> B683 | <input type="checkbox"/> B657 | <input type="checkbox"/> B615 | <input type="checkbox"/> B625 | | <input type="checkbox"/> SN | <input type="checkbox"/> BZ | <input type="checkbox"/> Blue | | | |
| | | | <input type="checkbox"/> AF632 | <input type="checkbox"/> B601 | <input type="checkbox"/> B637 | <input type="checkbox"/> B633 | <input type="checkbox"/> B624 | | <input type="checkbox"/> SHZ | | <input type="checkbox"/> White | | | |
| | | | <input type="checkbox"/> B610 | <input type="checkbox"/> B601L | <input type="checkbox"/> B643 | <input type="checkbox"/> B649 | <input type="checkbox"/> B681 | | | | <input type="checkbox"/> Red | | | |
| | | | <input type="checkbox"/> B607 | <input type="checkbox"/> B605 | <input type="checkbox"/> B658 | <input type="checkbox"/> AF633 | <input type="checkbox"/> B687 | | | | | | | |
| | | | <input type="checkbox"/> B608 | <input type="checkbox"/> B605L | <input type="checkbox"/> B659 | <input type="checkbox"/> B225 | <input type="checkbox"/> B682 | | | | | | | |
| | | | <input type="checkbox"/> B602 | <input type="checkbox"/> B606 | <input type="checkbox"/> B675 | <input type="checkbox"/> B653 | <input type="checkbox"/> B693 | | | | | | | |
| | | | | | | | | | | | | | | |
| | | | | | | | | | | | | | | |

Specifications:

B6RIC

AIR-SHUT - OPTION - TRIM TYPE - BAFFLE - REFLECTOR - TRIM/RING - GLASS

Sample of Catalog Number: B6RIC-AT-W-B630-W-WH

*For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.

Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: ELITE LIGHTING-SPEC-06-29-2011

Catalog Number:

Project Name:

Type:

Note:



DESCRIPTION

Thermally protected, IC rated specification grade remodel recessed housing. For remodeling installations where housing will be in direct contact with insulation. For fast and easy installation in existing plaster or mechanical ceilings from 1/2" to 1-3/8" thick. Four remodel clips are easily retractable for fixture removal if necessary. Junction box is provided with eight 1/2" KOs and four Romex knockouts with strain relief. Accommodates up to 75W PAR30, BR30, and A19 lamps.

SPECIFICATION


A. HOUSING - Die-formed, all aluminum construction for maximum heat dissipation and rust protection.

B. SOCKET - Medium base screw shell porcelain socket preinstalled on adjustable mounting bracket is designed to allow usage of different lamp types, as well as proper and consistent lamp positioning.

C. INSTALLATION - Four preinstalled spring clips which secure the housing firmly into ceiling to accommodate different ceiling thicknesses from 1/2" to 1-3/8".

D. JUNCTION BOX - UL listed for through-branch circuit wiring, provided with eight 1/2" KOs and four Romex knockouts with strain relief.

E. THERMAL PROTECTION - Standard thermal protection device guards against improper installation, overlamping and misuse of insulation material.

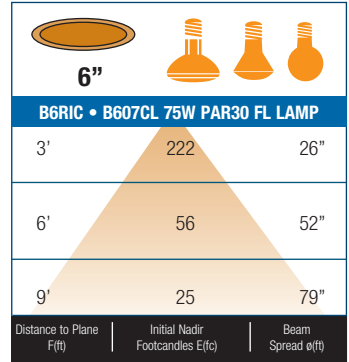

BEAM DIA. MEASURED AT 50% OF NADIR F.C.

FEATURES

- Thermally Protected remodel IC housing.
- Dependable, favorable design and effortless installation.
- Unit slips through 6-1/2" ceiling opening.
- Four preinstalled spring clips which secure the housing firmly into ceiling to accommodate different ceiling thickness from 1/2" to 1-3/8".
- Can be installed from below the ceiling.
- 7-1/4" height allows use in 2" x 8" joist construction.
- Wire through junction box.
- Adjustable socket bracket.
- Preinstalled socket cap provides electrical contact protection against dust, paint and over spray.

OPTIONS

AIR-SHUT

- Gasket to prevent air flow from heated or air conditioned spaces.
- Meets all national air flow requirements.



6" Incandescent Trims

(LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


elite LIGHTING

B630CP-CP
METAL STEPPED BAFFLE R30/PAR30



BAFFLE FINISH:
W, P, SN, CP, BZ


TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

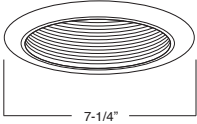


B620-ORANGE
GLASS TRIM



GLASS FINISH:
GREEN, YELLOW,
PINK, BROWN, NAVY
BLUE, ORANGE,
WHITE, RED

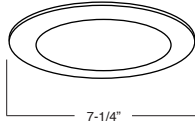


 B631P-WH
R30 PREMIUM PHENOLIC BAFFLE / METAL RING




BAFFLE FINISH:
W, P

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

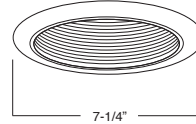

AF637W-WH
SELF FLANGE AIR-SHUT BAFFLE

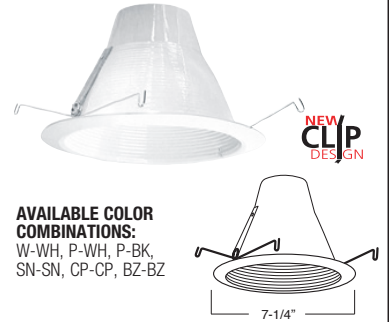

AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, P-BK,
SN-SN, CP-CP, BZ-BZ

AF631W-WH
SELF FLANGE AIR-SHUT BAFFLE



AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, P-BK,
SN-SN, CP-CP, BZ-BZ

AF639W-WH
SELF FLANGE AIR-SHUT BAFFLE



AVAILABLE COLOR COMBINATIONS:
W-WH

MATT WHITE FINISH

AF640W-WH
DEEP SELF FLANGE AIR-SHUT BAFFLE



AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, SN-SN,
CP-CP, BZ-BZ

AF632RG-WH
AIR-SHUT REFLECTOR



AVAILABLE COLOR COMBINATIONS:
CL-WH, CL-CH,
RG-WH, W-WH,
MB-WH, CP-CP, SN-SN


B610P-RG-WH
CONE REFLECTOR/BAFFLE TRIM



BAFFLE FINISH:
W, P

REFLECTOR FINISH:
CL, RG

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

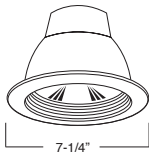

B607CP-WH
REFLECTOR R/PAR30



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN,
BZ, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ




B608CL-WH
CONE REFLECTOR A19



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN,
BZ, SHZ


TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

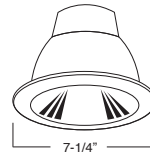

B602SN
EYEBALL



TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

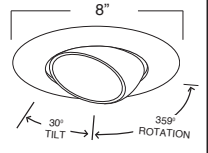


B609W-WH
REGRESSED EYEBALL WITH BAFFLE



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

EYEBALL FINISH:
WH, BK, SN, CP, CH, PB, BZ

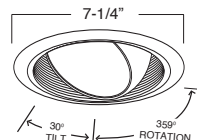


B619RG-PB
REGRESSED EYEBALL WITH REFLECTOR




REFLECTOR FINISH:
CL, RG, W, MB, CP, SN

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

EYEBALL FINISH:
WH, BK, SN, CP, CH, PB, BZ

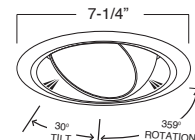


B646P-WH
EYEBALL WITH BAFFLE

 

BAFFLE FINISH:
W, P

TRIM/RING FINISH:
WH

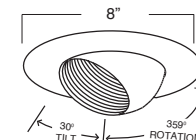


B616W-WH
PAR20 REGRESSED EYEBALL W/ BAFFLE



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

EYEBALL FINISH:
WH, BK, SN, CP, CH, PB, BZ

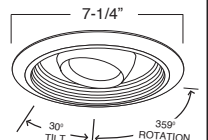

elite LIGHTING

Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011

6" Incandescent Trims

(LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

 
Project Name:

Type:


Note:

elite LIGHTING


B663PB
PAR30 GIMBAL RING



TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

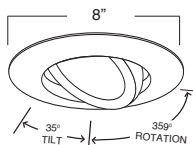


B673P-WH
PAR30 BAFFLE W/ GIMBAL RING

 


BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

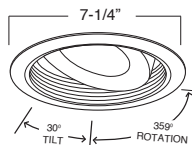


 B683CL-WH
PAR30 REFLECTOR W/ GIMBAL RING



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

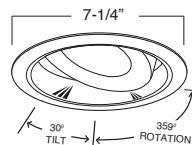


B601CP
METAL ALBALITE LENS



FOR
WET
LOCATION

LENS:
ALBALITE

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

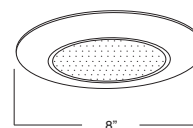


B601L
PLASTIC ALBALITE LENS



FOR
WET
LOCATION

LENS:
ALBALITE

TRIM/RING FINISH:
WHITE PLASTIC

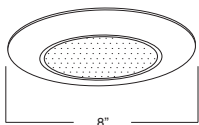


B605PB
METAL FRESNEL LENS



FOR
WET
LOCATION

LENS:
FRESNEL

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

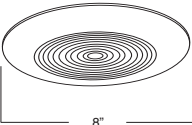


B605L
PLASTIC FRESNEL LENS



FOR
WET
LOCATION

LENS:
FRESNEL

TRIM/RING FINISH:
WHITE PLASTIC

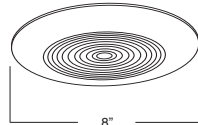


B606CP
METAL DROP OPAL LENS



FOR
WET
LOCATION

LENS:
DROP OPAL

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

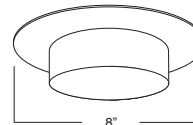


B606L
PLASTIC DROP OPAL LENS



FOR
WET
LOCATION

LENS:
DROP OPAL

TRIM/RING FINISH:
WHITE PLASTIC

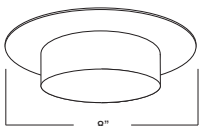


B635P-WH
BAFFLE W/ ALBALITE LENS



FOR
WET
LOCATION

BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

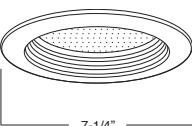


B636W-WH
BAFFLE W/ FRESNEL LENS



FOR
WET
LOCATION

BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

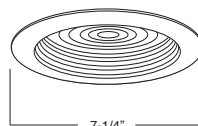


B642CL-WH
REFLECTOR W/ FRESNEL LENS



FOR
WET
LOCATION

REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

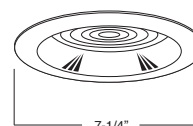


B641RG-WH
REFLECTOR W/ ALBALITE LENS



FOR
WET
LOCATION

REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

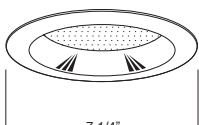


B656W-WH
BAFFLE W/ FROSTED DOME SHOWER LENS



FOR
WET
LOCATION

BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

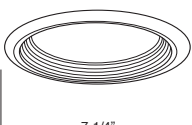

B657CL-WH
REFLECTOR W/ FROSTED DOME SHOWER LENS



FOR
WET
LOCATION

REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ




B637W-WH
BAFFLE W/ DROP OPAL LENS



FOR
WET
LOCATION

BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

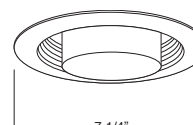

elite LIGHTING

Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011

6" Incandescent Trims

(LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

Project Name:

Type:

Note:


elite LIGHTING

B643RG-WH
REFLECTOR W/ DROP OPAL LENS



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

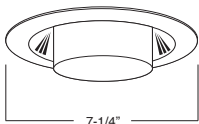


B658CL-WH
REFLECTOR W/ PRISMATIC LENS



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

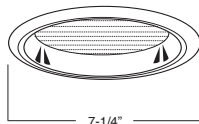


B659CL-WH
REFLECTOR W/ FROSTED LENS



REFLECTOR FINISH:
CL, RG, W, MB, CP,
SN, SHZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

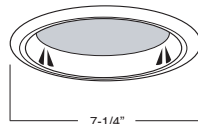


B675W-WH
BAFFLE W/ PRISMATIC LENS



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

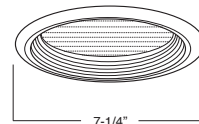


B676W-WH
BAFFLE W/ FROSTED LENS



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

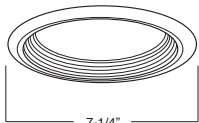


B612WH
SMOOTH FROST DOME SHOWER LENS



LENS:
FROSTED

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

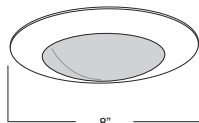


B645WH
DESIGNER POINT SHOWER LENS



LENS:
FROSTED/CLEAR

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

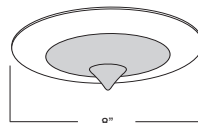


B648WH
DESIGNER CONE SHOWER LENS



LENS:
FROSTED

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

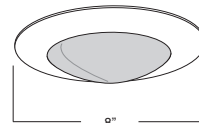


B652WH
SMOOTH FROST SHOWER LENS




LENS:
FROSTED


TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

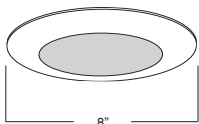

B603CP
R/PAR30 OPEN TRIM

 


TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ

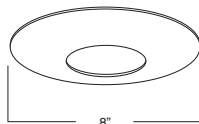

B615WH
DESIGNER PINHOLE




TRIM/RING FINISH:
WH, BK

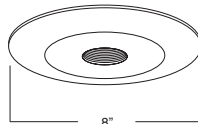

B633WH
R/PAR30 SPLAY TRIM



TRIM/RING FINISH:
WH, BK

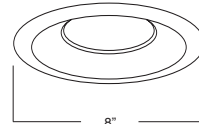


B649RG-WH
PAR20 REFLECTOR




REFLECTOR FINISH:
CL, RG, W, MB,
CP, SN

TRIM/RING FINISH:
WH, BK

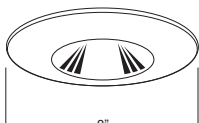

AF633CH
R/PAR30 OPEN TRIM

 

TRIM/RING FINISH:
WH, BK, SN, CP, CH,
PB, BZ




B225WH
OPEN TRIM STEPPED BAFFLE




BAFFLE FINISH:
W, P

TRIM/RING FINISH:
WH

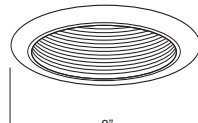


B653W-WH
BAFFLE WITH BAFFLE

 

BAFFLE FINISH:
W, P

TRIM/RING FINISH:
WH, BK, SN, CP,
CH, PB

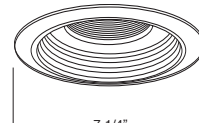

elite LIGHTING

Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011

6" Incandescent Trims

(LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

 
Project Name:

Type:

Note:


elite LIGHTING

**B651P-WH
PAR20 STEPPED BAFFLE**




BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH, BK

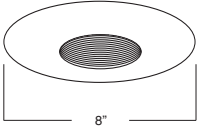


8"

 **B611W-WH
PAR30 BAFFLE WALL WASH**



AVAILABLE COLOR COMBINATIONS:
W-WH, P-WH, SN-SN, CP-CP, BZ-BZ

COVER FINISH:
WH, BK

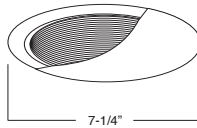


7-1/4"

**B647P-WH
DESIGNER BAFFLE WALL WASH PAR20**



BAFFLE FINISH:
W, P, SN, CP, BZ

TRIM/RING FINISH:
WH

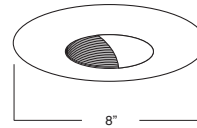


8"

**B644RG-WH
DESIGNER REFLECTOR WALL WASH PAR20**



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN

TRIM/RING FINISH:
WH

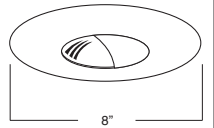


8"

**B650WH
DESIGNER WALL WASH**



TRIM/RING FINISH:
WH

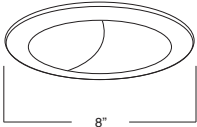

8"


**B622RG-WH
R/PAR30 WALL WASH REFLECTOR**



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN, SHZ

COVER FINISH:
WH

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

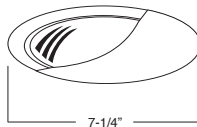

7-1/4"


**B625CL-WH
A-19 CONE REFLECTOR WALL WASH**



REFLECTOR FINISH:
CL, RG, W, MB, CP, SN, SHZ

COVER FINISH:
WH

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

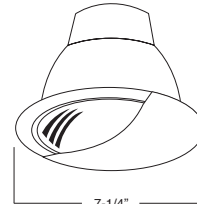

7-1/4"

**B624W-CL
CONE REFLECTOR BAFFLE WALL WASH**




BAFFLE FINISH:
W, P

REFLECTOR FINISH:
CL, RG

COVER FINISH:
WH

TRIM/RING FINISH:
WH, BK, SN, CP, CH, PB, BZ

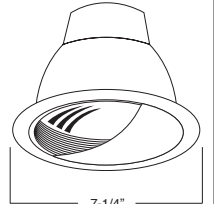


7-1/4"

**B681CP-WH
SQUARE BAFFLE TRIM**



BAFFLE FINISH:
W, P, SN, CP, BZ

 TRIM/RING FINISH:
WH, BK, SN, CP




7-1/2"

**B687CP-WH
SQUARE REFLECTOR TRIM**



REFLECTOR FINISH:
CL, RG, W, MB, SN, CP

 TRIM/RING FINISH:
WH, BK, SN, CP




7-1/2"

**B682WH
SQUARE EYEBALL TRIM**



 TRIM/RING FINISH:
WH




7-1/2"

**B693WH
SQUARE PAR30 GIMBAL TRIM**



 TRIM/RING FINISH:
WH




7-1/2"

**B688WH
SQUARE ALBALITE SHOWER TRIM**



LENS:
WHITE

 TRIM/RING FINISH:
WH




7-1/2"

**B685WH
SQUARE FRESNEL SHOWER TRIM**



LENS:
CLEAR

 TRIM/RING FINISH:
WH




7-1/2"

**B696WH
SQUARE DROP OIPAL SHOWER TRIM**



LENS:
WHITE

 TRIM/RING FINISH:
WH




7-1/2"

**B689WH
SQUARE DESIGNER CONE SHOWER LENS**



LENS:
FROSTED

 TRIM/RING FINISH:
WH



7-1/2"

elite LIGHTING

Submittal form is available @ www.iuseelite.com
Tel: 323-888-1973 • Fax: 323-888-1977

Specifications and Dimensions
subject to change without notice.

REV: MAXILUME-SPEC-05-26-2011

6" Incandescent Trims

(LAMP WATTAGE: (1) MAXIMUM 75W R/PAR30, 60W A19, 65W BR30)

Catalog Number:

 
Project Name:

Type:

Note:

elite LIGHTING


B680WH SQUARE DESIGNER POINT LENS



FOR
WET
LOCATION

LENS:
FROSTED/CLEAR

TRIM/RING FINISH:
WH

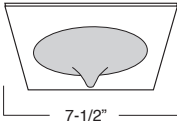

| BAFFLE | REFLECTOR | TRIM RING |
|------------------------|------------------------|------------------------|
| W White | CL Chrome | WH White |
| P Black | RG Gold | BK Black |
| SN Satin Nickel | W White | SN Satin Nickel |
| CP Copper | MB Black | CP Copper |
| BZ Bronze | CP Copper | CH Chrome |
| | SN Satin Nickel | PB Polish Brass |
| | | BZ Bronze |

**For custom baffle, reflector, trim ring, glass color and lens options, please consult factory.*