


Hangers

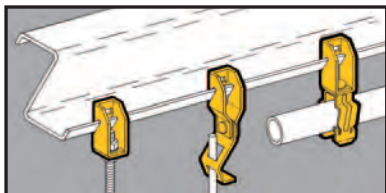

- Compensates for angle of purlin lip.
- Allows for parallel conduit runs or vertical support drops.
- Riveted fasteners will rotate 360°.
- Maximum Purlin thickness of $\frac{3}{32}$ ".

"Z" Purlin Hangers

BF13



BF12



UPC/Part Number	Catalog Number	Description	Static Load Cap. Lbs.	Box Qty.
781011 18345	BF13	With $\frac{1}{4}$ " Hole	100	100
781011 18340	BF12	For "S" Hooks	100	100



Guide-Rite™
Fastener
BG Series



Push-Type
BP Series

UPC/Part Number	Catalog Number	Conduit Size EMT & Rigid	Static Load Cap. Lbs.	Box Qty.
781011 18445	BG-6-F13*	$\frac{3}{8}$ "	100	100
781011 18520	BG-8-12-F13	$\frac{1}{2}$ ", $\frac{3}{4}$ "	100	100
781011 18590	BG-16-F13	1"	100	100
781011 18675	BG-20-F13	$1\frac{1}{4}$ "	100	50
781011 19290	BP-8-F13	$\frac{1}{2}$ " EMT	25	100
781011 19390	BP-12-F13	$\frac{3}{4}$ " EMT $\frac{1}{2}$ " IMC, Rigid	25	100
781011 19480	BP-16-F13	1" EMT $\frac{3}{4}$ " IMC, Rigid	25	50

* BG-6 will accept the following range $\varnothing.420 - \varnothing.675$:
14/2 thru 10/4 MC/AC cable and $\frac{5}{16}$ or $\frac{3}{8}$ flexible conduit

Read safety/installation instruction sheets in packages before use.



Universal Beam Fasteners



UPC/Part Number	Catalog Number	Description	Static Load Cap.	Box Qty.
781011 18920	BH1-F12	#8 Wire or 1/4" Plain Rod	100 Lbs.	100
781011 18960	BH2-F12	3/8" Plain Rod	100 Lbs.	100




UPC/Part Number	Catalog Number	Threaded Rod Size	Static Load Cap.	Box Qty.
781011 19000	BH4-F12	1/4"	100 Lbs.	100
781011 19080	BH6-F12	3/8"	100 Lbs.	100
781011 19040	BH5-F12*	1/4" & 3/8"	100 Lbs.	100

*Nuts Required.

Note: BH4 and BH6 have thread impressions.

- Compensates for angle of purlin lip.
- Attaches MC, AC, sizes 14/2 through 10/3 or 3/8" FMC to "Z" Purlins up to 3/32" thick.
- Fastener will rotate 360°.
- Simply installed with a hammer.

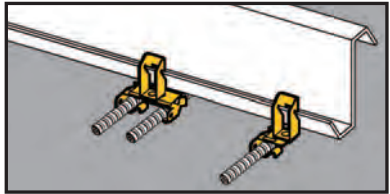

Cable To "Z" Purlin Flange Hangers



BX4-F13




BX4M-F13



UPC/Part Number	Catalog Number	Description	Flange Thickness	Box Qty.
781011 01188	BX4-F13	Single Runs	Thru 3/32"	100
781011 01204	BX4M-F13	Double Runs	Thru 3/32"	100

Read safety/installation instruction sheets in packages before use.

Hangers

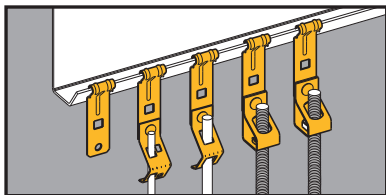

- Suspend wire, or plain and threaded rod from "Z" Purlins.
- Fits "Z" Purlins 1/16" to 1/4" thick.
- Simply installed with a hammer.
- Static Load Capacity: 160 Lbs.

"Z" Purlin Flange Hangers



UPC/Part Number	Catalog Number	Description	Box Qty.
781011 04271	BF4	For "S" Hooks, Bolting Straps and Wrap Wire	100



UPC/Part Number	Catalog Number	Description	Box Qty.
781011 04164	BT3	Installation Tool for BF4 Hangers (Insert 1/2" Rigid conduit for installation)	1

Read safety/installation instruction sheets in packages before use.

“Z” Purlin Flange Hangers



UPC/Part Number	Catalog Number	Description	Box Qty.
781011 04274	BH1-F4	#8 Wire or 1/4" Plain Rod	100
781011 04276	BH2-F4	3/8" Plain Rod	100




UPC/Part Number	Catalog Number	Threaded Rod Size	Box Qty.
781011 04286	BH4-F4	1/4"	100
781011 04280	BH6-F4	3/8"	100
781011 04278	BH5-F4*	1/4" - 3/8"	100

* Nuts required.

Note: BH4 & BH6 have thread impressions.

Read safety/installation instruction sheets in packages before use.

Hangers

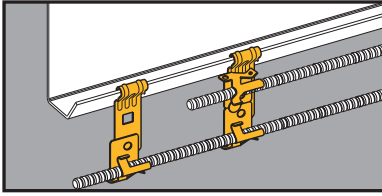

- Attaches MC, AC, sizes 14/2 thru 10/3 or 3/8" FMC to "Z" Purlins.
- Fits "Z" Purlin flanges 1/16" to 1/4" thick.
- Fastener will rotate 360°.

Cable To "Z" Purlin Flange Hangers



UPC/Part Number	Catalog Number	Description	Box Qty.
781011 04931	BX4-F4	Single Runs	100

These products are designed for positioning only. No load rating.




UPC/Part Number	Catalog Number	Description	Box Qty.
781011 04932	BX4M-F4	Double Runs	100

This product is designed for positioning only. No load rating.

Read safety/installation instruction sheets in packages before use.

- Secures and supports multiple runs of MC/AC cable to 'Z' purlins.
- Effectively organizes cables and eliminates derating issues.
- Retention tab is open for easy loading and unloading and contains cables when bent in place.
- Load Capacity: 50 lbs.

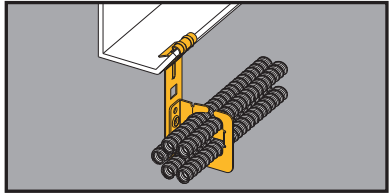

MC/AC Cable Carrier to 'Z' Purlin Flange Hanger



UPC/Part Number	Catalog Number	Cable Diameter & Number Of Runs	Box Qty.
782051 44084	BRC51-F4	.430" to .560" Up to 4 Runs	25
782051 44085	BRC52-F4	.430" to .560" Up to 9 Runs	25
782051 44086	BRC53-F4	.560" to .690" Up to 7 Runs	25

Read safety/installation instruction sheets in packages before use.