


Conduit & Cable

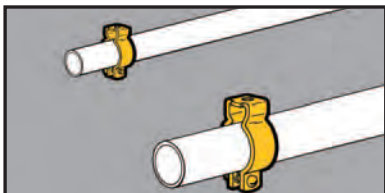

- For use with 1/2" thru 4" Conduit.
- Static Load Capacity: 400 lbs.
- Now available in DURA-COPPER™ finish - add DCU to part number.
- Finish: Zinc-Plated

Conduit Hangers



With Retained Bolt
And
Thread Impression



UPC/Part Number	Catalog Number	Trade Size	Conduit Size		Box Qty.
			EMT	Rigid	
781011 19800	BL1400*	0	1/2"	1/2"	100
781011 19801	BL1410*	1	3/4"	3/4"	100
781011 19802	BL1420*	2	1"	1"	100



With Bolt And Nut




UPC/Part Number	Catalog Number	Trade Size	Conduit Size		Box Qty.
			EMT	Rigid	
781011 19803	BL1425*	2.5	1 1/4"	--	100
781011 19804	BL1430*	3	1 1/2"	1 1/4"	100
781011 19805	BL1440†	4	--	1 1/2"	50
781011 19806	BL1450†	5	2"	2"	50
781011 19807	BL1460†	6	2 1/2"	2 1/2"	25
781011 19808	BL1470†	7	3"	3"	25
781011 19809	BL1480†	8	3 1/2"	3 1/2"	10
781011 19810	BL1490†	9	4"	4"	10

* 9/32" mounting hole. † 11/32" mounting hole.

Read safety/installation instruction sheets in packages before use.

- For use with 1/2" thru 4" Conduit.
- Static Load Capacity: 400 lbs.
- Material: Type 304 Stainless Steel

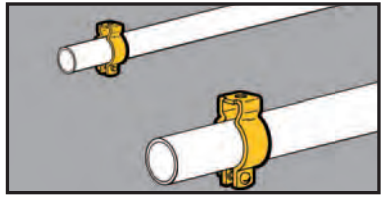

Stainless Steel Conduit Hangers



With Retained Bolt
And
Thread Impression



UPC/Part Number	Catalog Number	Trade Size	Conduit Size		Box Qty.
			EMT	Rigid	
781011 57490	BL1400-SS4*	0	1/2"	1/2"	25
781011 57497	BL1410-SS4*	1	3/4"	3/4"	25
781011 57506	BL1420-SS4*	2	1"	1"	25



With Bolt And Nut



UPC/Part Number	Catalog Number	Trade Size	Conduit Size		Box Qty.
			EMT	Rigid	
781011 87485	BL1425-SS4*	2.5	1 1/4"	--	25
781011 57517	BL1430-SS4*	3	1 1/2"	1 1/4"	25
781011 57525	BL1440-SS4†	4	--	1 1/2"	25
781011 57535	BL1450-SS4†	5	2"	2"	10
781011 57546	BL1460-SS4†	6	2 1/2"	2 1/2"	10
781011 87481	BL1470-SS4†	7	3"	3"	10
781011 87486	BL1480-SS4†	8	3 1/2"	3 1/2"	10
781011 87482	BL1490-SS4†	9	4"	4"	10

* 9/32" mounting hole. † 11/32" mounting hole.

Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.