



Project:

Type:

Prepared By:

Date:



UPC: 019813750491

Features and Benefits

- Energy efficient replacement for incandescent and halogen reflector lamps
- Constructed from durable plastic which lowers risk of breakage
- Rated for use in enclosed and open fixtures in dry or damp locations
- Frosted lens produces smooth diffuse light
- Longer lifespan compared to legacy equivalents minimizes replacement and maintenance costs
- ENERGY STAR Compliant
- Dimmable with common dimmer types (see Dimmer Compatibility List)

Technical Specifications

Performance

Product Type:
Reflector

Input Wattage:
15W

Lumens:
1,100lm

Efficacy:
73lm/W

L70 Lifespan:
25,000-Hour LED lifespan based on IES LM-70 results

Wattage Equivalency:
85W

LED Characteristics

Color Accuracy (CRI):
80

Color Temperature:
3000K

Beam Angle:
110°

Electrical
Power Factor:
>0.9

Dimmable:
Yes, down to 20%

Input Voltage:
120V

Operating Temperature:
-20°C to 40°C

Construction

Shape:
BR40

Enclosure Material:
Plastic

Housing Finish:
White

Lens Finish:
Frosted

Installation

Base Type:
E26 Edison

Other

Technology EQ:
Incandescent

3-Year, No-Compromise Warranty:

RAB warrants that our LED products will be free from defects in materials and workmanship for a period of three (3) years from the date of delivery to the end user, including coverage of light output, color stability, driver performance and fixture finish. RAB's warranty is subject to all terms and conditions found at rablighting.com/warranty.

Compliance

UL Listed:
Yes

Environment:
Damp / Enclosed

BR40-15-830-DIM



Technical Specifications (continued)

Energy Star ID:

2329468

RoHS:

Mercury and UV free. RoHS-compliant components.

FCC:

Complies with Part 15B of the FCC Rules


Certification Model Number:

BR40-15-830-DIM

Case and Pallet Dimensions

	QTY	LENGTH (in)	WIDTH (in)	HEIGHT (in)
CASE	6	15.8	10.6	7
PALLET	360	47.2	37	41.8

Dimension

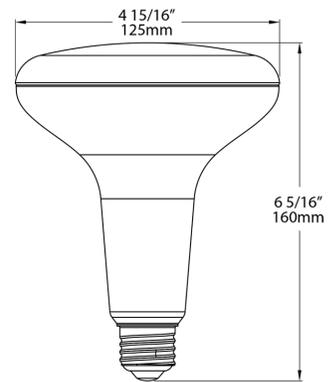

Light Distribution

