


# Eaton BR430

Catalog Number: BR430

Eaton BR thermal magnetic circuit breaker, Type BR 1-Inch plug-on circuit breaker, 30 A, 10 kAIC, Four-pole, 120/240V, BR, Independent, #14-4 AWG Cu/Al, Q28, BR, Type BR Loadcenters

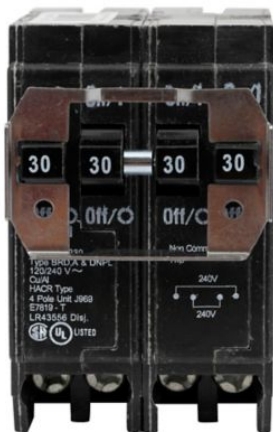

## General specifications

<b>Product Name</b>	<b>Catalog Number</b>
Eaton BR thermal magnetic circuit breaker	BR430
	<b>UPC</b>
	786676372206
<b>Product Length/Depth</b>	<b>Product Height</b>
3 in	3 in
<b>Product Width</b>	<b>Product Weight</b>
2 in	0.5 lb
<b>Compliances</b>	<b>Certifications</b>
Federal Specifications Classification W-C375	UL 489
	<b>Catalog Notes</b>
	Non- CTL. Breaker does not have rejection tab feature.

## defaultTaxonomyAttributeLabel

### Type

Type BR 1-Inch plug-on circuit breaker

### Special features

Used with Type BR Loadcenters

### Amperage Rating

30 A

### Voltage rating

120/240 V

### Trip Type

Independent

### Circuit breaker type

BR

### Used with

Type BR Loadcenters

### Mounting Method

Plug-on

### Interrupt rating

10 kAIC

### Main circuit breaker

BR

### Wire size

#14-4 AWG Cu/Al

### Number of poles

Four-pole

### Quantity

28

## Resources

### Brochures

[Loadcenters and Circuit Breakers](#)

### Catalogs

[Eaton's Volume 1—Residential and Light Commercial](#)

### Specifications and datasheets

[Eaton Specification Sheet - BR430](#)



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com  
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)