


Eaton BRL215CAF

Catalog Number: BRL215CAF

Eaton BR AFCI circuit breaker, FIRE-GUARD AFCI Combination circuit breaker, 15 A, 10 kAIC, Two-pole, 120 V, 120/240 V, BR, Common trip, #14-4 AWG Cu/Al, Type BR Loadcenters

General specifications

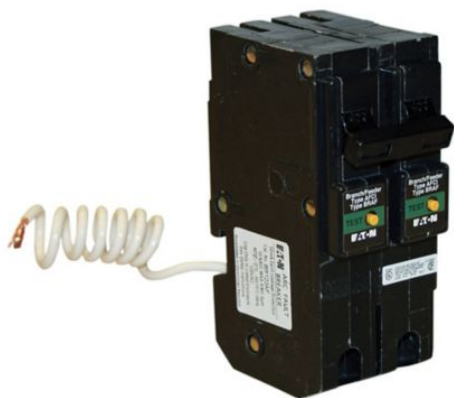

Product Name

Eaton BR AFCI circuit breaker

Catalog Number

BRL215CAF

UPC

786685495156

Product Length/Depth

6 in

Product Height

1.25 in

Product Width

3.5 in

Product Weight

0.45 lb

Warranty

10 year

Compliances

Federal Specifications Classification W-C375

Certifications

UL 1699

Catalog Notes

Combination Fireguard/Arc Fault, Common trip refers to two-pole 240V load application sourced by 120/240V, Independent trip refers to two-pole multi-wire, home run or shared neutral circuits.

Type

FIRE-GUARD AFCI Combination circuit breaker

Special features

Combination arc fault

Amperage Rating

15 A

Voltage rating

120/240 V

Trip Type

Common trip

Used with

Type BR Loadcenters

Interrupt rating

10 kAIC

Main circuit breaker

BR

Wire size

#14-4 AWG Cu/Al

Number of poles

Two-pole

Brochures

Loadcenters and Circuit Breakers

Type BR Arc Fault Circuit Breakers and Loadcenters

Catalogs

Eaton's Volume 1—Residential and Light Commercial

Specifications and datasheets

Eaton Specification Sheet - BRL215CAF

Type BR (1") Combination Arc Fault Circuit Interrupter