


Eaton BRP20L200

Catalog Number: BRP20L200

Eaton Eaton BR main lug loadcenter,Main lug only,200 A,X3,Aluminum, NEMA 1,Metallic,10kAIC,CSR2200,NEMA1,40 Circuits,Twenty-four pole,20 Spaces,Two hots,a neutral,and a ground,Single-phase,Type BR 1-inch breakers,120/240V,#1–300 kcmil

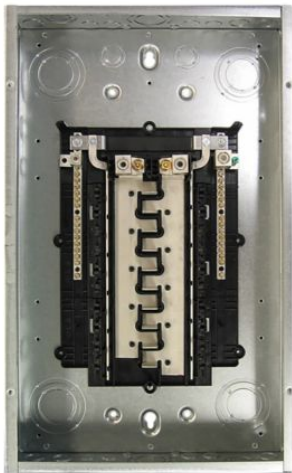

General specifications

Product Name	Catalog Number
Eaton BR main lug loadcenter	BRP20L200
UPC	Product Length/Depth
786689053260	23 in
Product Height	Product Width
3.88 in	14.31 in
Product Weight	Warranty
21 lb	10 year
Certifications	
UL 50	
UL 67	

defaultTaxonomyAttributeLabel

Type

MLO

Amperage Rating

200 A

Bus material

Aluminum

Cover

Cover included

Main circuit breaker

CSR2200

Number of circuits

40

Number Of Poles

Single-pole

Number of spaces

20

Phase

Single-phase

Used with

Type BR 1-inch breakers

Voltage rating

120/240V

Box size

X3

Enclosure

NEMA 1

Enclosure material

Metallic

Interrupt rating

10 kAIC

NEMA rating

NEMA 1

Number of wires

Two hots, neutral and ground

Resources

Brochures

[Loadcenters and Circuit Breakers](#)

Specifications and datasheets

[Eaton Specification Sheet - BRP20L200](#)



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are
property of their respective
owners.




[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)

Eaton BRP20L200

Catalog Number: BRP20L200

Eaton Eaton BR main lug loadcenter,Main lug only,200 A,X3,Aluminum, NEMA 1,Metallic,10kAIC,CSR2200,NEMA1,40 Circuits,Twenty-four pole,20 Spaces,Two hots,a neutral,and a ground,Single-phase,Type BR 1-inch breakers,120/240V,#1–300 kcmil

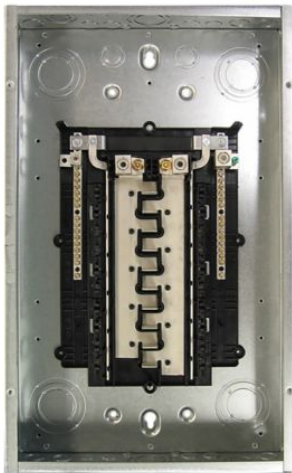

General specifications

Product Name	Catalog Number
Eaton BR main lug loadcenter	BRP20L200
UPC	Product Length/Depth
786689053260	23 in
Product Height	Product Width
3.88 in	14.31 in
Product Weight	Warranty
21 lb	10 year
Certifications	
UL 50	
UL 67	

defaultTaxonomyAttributeLabel

Type

MLO

Amperage Rating

200 A

Bus material

Aluminum

Cover

Cover included

Main circuit breaker

CSR2200

Number of circuits

40

Number Of Poles

Single-pole

Number of spaces

20

Phase

Single-phase

Used with

Type BR 1-inch breakers

Voltage rating

120/240V

Box size

X3

Enclosure

NEMA 1

Enclosure material

Metallic

Interrupt rating

10 kAIC

NEMA rating

NEMA 1

Number of wires

Two hots, neutral and ground

Resources

Brochures

[Loadcenters and Circuit Breakers](#)

Specifications and datasheets

[Eaton Specification Sheet - BRP20L200](#)



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are
property of their respective
owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)