


Eaton BRP30L125

Catalog Number: BRP30L125

Eaton Eaton BR main lug loadcenter, Indoor, Main lug only, 125 A, X5, Aluminum, Gray, NEMA 1, Metallic, 10kAIC, BR2125, Surface, flush, 60 Circuits, 30 Spaces, Two hots, a neutral, and a ground, Single-phase, 120/240V, #6-2/0

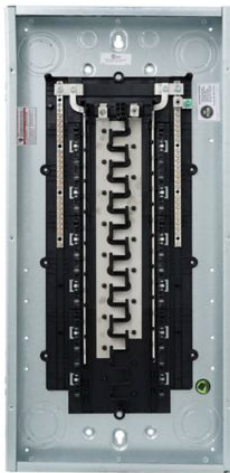

General specifications

Product Name	Catalog Number
Eaton BR main lug loadcenter	BRP30L125
UPC	Product Length/Depth
786689052874	29.12 in
Product Height	Product Width
3.88 in	16 in
Product Weight	Warranty
25.65 lb	10 year
Certifications	
UL 50	
UL 67	

defaultTaxonomyAttributeLabel

Type

MLO

Amperage Rating

125 A

Bus material

Aluminum

Cover

Cover included

Main circuit breaker

BR2125

Mounting

Surface, flush

Number of circuits

60

Number Of Poles

Single-pole

Number of spaces

30

Phase

Single-phase

Used with

Type BR 1-inch breakers

Voltage rating

120/240V

Box size

X5

Color

Gray

Enclosure

NEMA 1

Enclosure material

Metallic

Interrupt rating

10 kAIC

Resources

Brochures

[Loadcenters and Circuit Breakers](#)

Specifications and datasheets

[Eaton Specification Sheet - BRP30L125](#)

NEMA rating

NEMA 1

Number of wires

Two hots, neutral and ground



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com

© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)