

# Eaton BRP60B200R

Catalog Number: BRP60B200R

Plug-on neutral main circuit breaker  
loadcenter,200A,X10,Aluminum,Cover included,NEMA  
3R,Metallic,10 kAIC,BR,120 circuits,Single pole,60 spaces,Three-  
wire,Single-phase,Combination,NEMA 3R,Type BR 1-inch  
breakers,120/240V

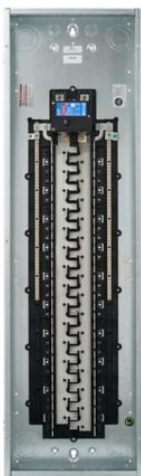


Photo is representative

## General specifications

Product Name	Catalog Number
Eaton BR main breaker loadcenter	BRP60B200R
UPC	Product Length/Depth
786689059088	48.75 in
Product Height	Product Width
5.5 in	14.31 in
Product Weight	Warranty
35 lb	10 year
Certifications	
UL 67	
UL 50	

defaultTaxonomyAttributeLabel

Type

Plug-on neutral main circuit breaker loadcenter

Amperage Rating

200 A

Bus material

Aluminum

Cover

Cover included

Main circuit breaker

CSR

Number of circuits

120

Number Of Poles

Single-pole

Number of spaces

60

Phase

Single-phase

Mounting

Combination

Used with

Type BR 1-inch breakers

Voltage rating

120/240 V

Box size

X10

Enclosure

NEMA 3R

Enclosure material

Metallic

Interrupt rating

25 kAIC

Number of wires

3

Resources

Brochures

[Loadcenters and Circuit Breakers](#)

Specifications and datasheets

[Eaton Specification Sheet - BRP60B200R](#)

NEMA rating  
NEMA 3R



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com  
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.  
All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://Eaton.com/socialmedia)