



# Conduit & Cable

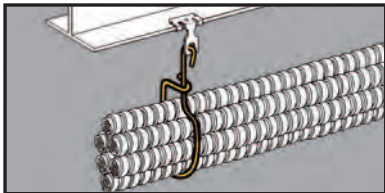


- Designed to support multiple runs of MC, AC, FMC or communication cable.
- Static Load Capacity:  
BX2 - 50 lbs.  
BX6 & BX24 - 75 Lbs.
- Finish: Zinc Plated

## Flexible Cable Support

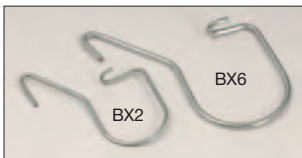

UPC/Part Number	Catalog Number	Description	Box Qty.
782051 04934	<b>BX2</b>	Usable Area = 2 sq. in.	100
781011 19765	<b>BX6</b>	Usable Area = 4 sq. in.	100
781011 19766	<b>BX24</b>	Usable Area = 13 sq. in.	100

Conduit & Cable

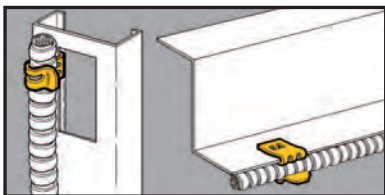

- Fastens flexible conduit and other small cables to beam flanges, bar joists or metal studs.
- Cable O.D. range of 0.42" to 0.70".
- Maximum flange thickness  $5/32$ ".


## Flexible Conduit/Cable Fasteners



UPC/Part Number	Catalog Number	Description	Box Qty.
781011 19770	<b>BX9</b>	Flexible Conduit Fastener	100

Read safety/installation instruction sheets in packages before use.

- Secures cable along flanges 1/16" to 3/4" thick.
- The BFA flange adapters attach BXS series to thicker flanges.
- BX\_-67 accepts 14/2, 12/2 & 10/2 romex with ground.
- BX\_-1011 accepts 14/2, 12/2 & 10/2 romex with ground.
- BX\_-1214 accepts 10/3, romex with ground.
- Finish: Zinc Plated

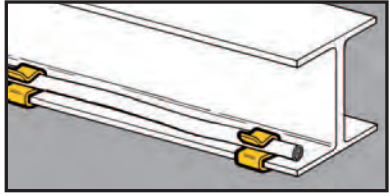

## Flexible Conduit/ Cable Fasteners

BFA Series  
(For Use with  
BXS Series  
Only)



BXS  
Series



BXL  
Series



UPC/Part Number	Catalog Number	Flange Thickness	Cable Diameter	Box Qty.
781011 19973	<b>BXS-67</b>	1/16" - 5/32"	.218 to .281	100
781011 19974	<b>BXS-89</b>	1/16" - 5/32"	.290 to .375	100
781011 19975	<b>BXS-1011</b>	1/16" - 5/32"	.375 to .437	100
781011 19976	<b>BXS-1214</b>	1/16" - 5/32"	.444 to .560	100
781011 19977	<b>BXS-1519</b>	1/16" - 5/32"	.500 to .718	100
781011 19978	<b>BXS-2024</b>	1/16" - 5/32"	.748 to .945	100
781011 19979	<b>BXS-2530</b>	1/16" - 5/32"	.968 to 1.250	100
781011 19980	<b>BXM-67</b>	5/32" - 9/32"	.218 to .281	100
781011 19981	<b>BXM-89</b>	5/32" - 9/32"	.290 to .375	100
781011 19982	<b>BXM-1011</b>	5/32" - 9/32"	.375 to .437	100
781011 19983	<b>BXM-1214</b>	5/32" - 9/32"	.444 to .560	100
781011 19984	<b>BXM-1519</b>	5/32" - 9/32"	.500 to .718	100
781011 19985	<b>BXM-2024</b>	5/32" - 9/32"	.748 to .945	100
781011 19986	<b>BXM-2530</b>	5/32" - 9/32"	.968 to 1.250	100
781011 19987	<b>BXL-67</b>	5/16" - 1/2"	.218 to .281	100
781011 19988	<b>BXL-89</b>	5/16" - 1/2"	.290 to .375	100
781011 19989	<b>BXL-1011</b>	5/16" - 1/2"	.375 to .437	100
781011 19990	<b>BXL-1214</b>	5/16" - 1/2"	.444 to .560	100
781011 19991	<b>BXL-1519</b>	5/16" - 1/2"	.500 to .718	100
781011 19992	<b>BXL-2024</b>	5/16" - 1/2"	.748 to .945	100
781011 19993	<b>BXL-2530</b>	5/16" - 1/2"	.968 to 1.250	100
781011 19955	<b>BFA-1215</b>	1/2" - 5/8"	--	100
781011 19956	<b>BFA-1520</b>	5/8" - 3/4"	--	100

Read safety/installation instruction sheets in packages before use. These products are designed for positioning only. No load rating.