



Transformer Specifications	
PRIMARY VOLTAGE(S)	230/460 (TRIPLE RATED)
SECONDARY VOLTAGE(S)	115
RATED V/A	75
RATED FREQUENCY	50/60
INSULATION CLASS	105
AGENCY APPROVALS	UL, CUL
ESTIMATED WEIGHT	3.4 LBS

TEST REQUIREMENTS	
WINDING	H4-H3 H2-H1 X2-X1
D.C. VOLTS	240 240 133.2
LEAD VOLTS	240 240 120
F.L. AMPS	0.211 0.211 0.625
HI-POT	3000V 1800V
EXCITING AMPS	0.26AMPS @ 240 VOLTS, 50HZ
EXCITING WATTS	6.8 MAX

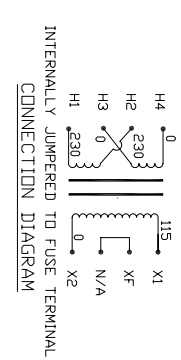

NOTE:  
1. ALL MEASUREMENTS IN INCHES (MM)



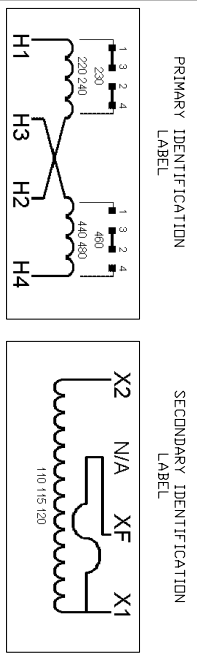MAIN PRODUCT IDENTIFICATION LABEL

**Cutler-Hammer** INDUSTRIAL CONTROL TRANSFORMER  
75VA 50/60Hz  
TEMP CL. 105°C  
CAT. NO. C0075E2A  
SERIES 2  
34095

UNLESS OTHERWISE SPECIFIED		EATON CORPORATION - CONFIDENTIAL AND PROPRIETARY	
DIMENSIONS IN INCHES	APPD S.CASTRO	DATE	11/06/08
ONE PLACE DEC	APPD E.ROBLES	DATE	11/06/08
TWO PLACE DEC	APPD C.CASTORENA	DATE	11/06/08
ANGLES	APPD	DATE	
VOLTAJE	APPD	DATE	
FINISH	APPD	DATE	
ASSIGNMENT	APPD	DATE	
FORCE/TORQUE/SPEED	APPD	DATE	
TEMPERATURE	APPD	DATE	
DIMENSIONS TO BE INTERPRETED IN ACCORDANCE WITH ASME Y14.5M-1994	APPD	DATE	
THIRD ANGLE PROJECTION	APPD	DATE	

TITLE		EATON CORPORATION - CONFIDENTIAL AND PROPRIETARY	
SIZE	B	DWG NO	C0075E2A
SCALE		PRODUCT CODE	
		PARTS LIST	
		PRODUCT CODE	
		SHEET NO	1 OF 1