

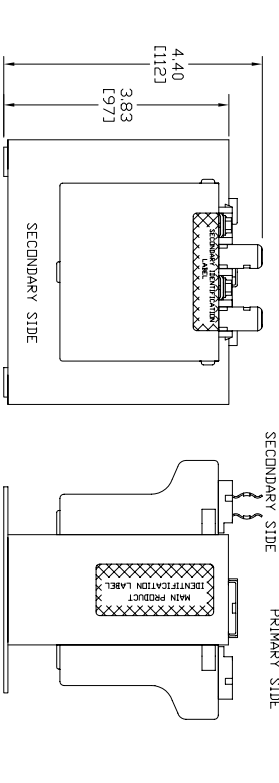


4 3 2 1


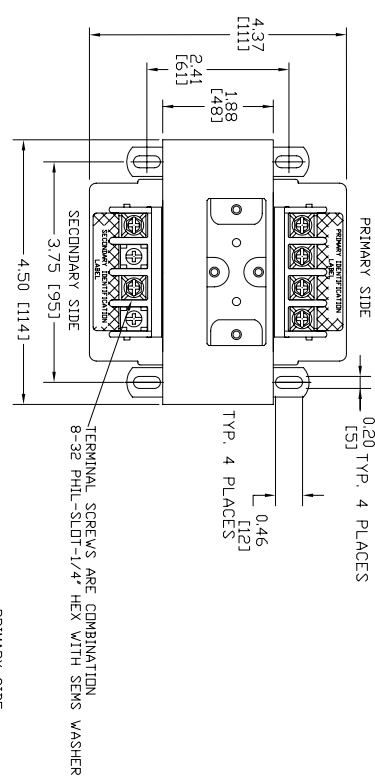


Transformer Specifications	
PRIMARY VOLTAGE(S)	200x460 (TRIPLE RATED)
SECONDARY VOLTAGE(S)	115
RATED V.A.	200
RATED FREQUENCY	50/60
INSULATION CLASS	130
AGENCY APPROVALS	UL, CUL
ESTIMATED WEIGHT	8.9 LBS

TEST REQUIREMENTS	
WINDING	H4-H3 H2-H1 X2-X1
D.C. VOLTS	240 240 130.4
L/DAD VOLTS	240 240 120
F.L. AMPS	0.530 0.530 1.667
HI-POT	3000V 1800V
EXCITING AMPS	0.42AMPS @ 240 VOLTS, 50HZ
EXCITING WATTS	200

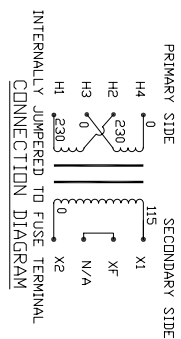

NOTE:
1. ALL MEASUREMENTS IN INCHES (MM)

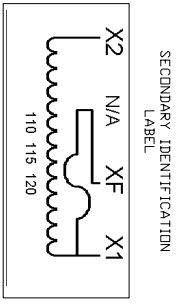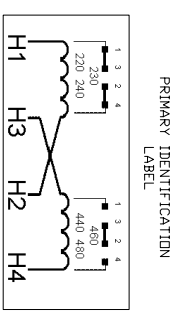

Culler-Hammer
INDUSTRIAL CONTROL TRANSFORMER
200V/VA 50/60Hz
TEMP CL 130°C
CAT. NO. C0200E2A
SERIES 2
35081
B200-2106-1F

UNLESS OTHERWISE SPECIFIED	
DIMENSIONS IN INCHES	ONE PLACE DEC
TWO PLACE DEC	±0.01
THREE PLACE DEC	±0.002
ANGLES 24x 0x3	±0.02
ANGLES 3x 0x3	±0.03
VOLTAGE	±3%
RESISTANCE	±2%
AVERAGE	±1%
FORCE/TORQUE/SPEED	±10%
TEMPERATURE	±1/2°F/1°F
TIME	±1%
DIMENSIONS TO BE INTERPRETED IN ACCORDANCE WITH	ASME Y14.5M-1994
(X) (X) SYMBOL DEFINITIONS PER DRAWING CASE/72	
(S) THIRD ANGLE PERSPECTIVE	

DRAYER/DESIGNER	DATE
S. CASTRO	11/06/08

APPD	DATE
EROBLES	11/06/08

APPD	DATE
C.CASTORENA	11/06/08

ENGR REF	TITLE
	MTE CONTROL TRANSFORMER 200 VA SERIES 2

SIZE	SCALE	PARTS LIST	PRODUCT CODE	SHEET NO
B			C0200E2A	1 OF 1

REVISION DT1109
E00 JACO-FRIBER REV. 05/03/08
4 3 2 1
© 2008 Eaton Corporation. All Rights Reserved