


# Eaton C25BNB240T

Catalog Number: C25BNB240T

Eaton definite purpose contactor, Quick, 40A, 277 Vac, 60 Hz, Open with metal mounting plate, Compact, two-pole, 40A, Contactor, Two-pole, 50A, Binding head screw and quick connect terminals (side-by-side), Non-reversing

## General specifications

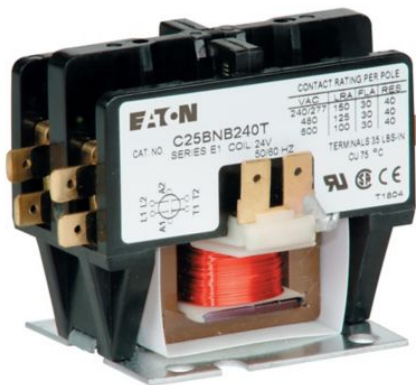

Product Name	Catalog Number
Eaton definite purpose contactor	C25BNB240T
UPC	Product Length/Depth
786685116105	2.32 in
Product Height	Product Width
3.19 in	1.97 in
Product Weight	Warranty
0.6 lb	1 year
Compliances	Certifications
RoHS Compliant	CSA Certified
	UL Recognized

## defaultTaxonomyAttributeLabel

### Amperage Rating

40A

### Number Of Poles

Two-pole

### Type

Non-reversing

### Coil

24 Vac, 50/60 Hz

### Enclosure

Open with metal mounting plate

### Frame size

Compact, two-pole

### Inductive full load

40 A

### Model

Contacto

### Resistive load

50 A

### Terminals

Binding head screw and quick connect terminals (side-by-side)

### Connection

Quick

## Resources

### Catalogs

[Eaton's Volume 5—Motor Control and Protection](#)

### Drawings

[C25BNB 2D Drawing Xchange](#)

[C25BNB 2D PDF](#)

[C25BNB AutoCAD 2D Footprint](#)

[C25BNB 3D Model Xchange](#)

[C25BNB AutoCAD 2D Footprint \(mm\)](#)

[C25BNB 3D Inventor](#)

### Specifications and datasheets

[Quick Selector - Definite Purpose Contactors](#)

[Eaton Specification Sheet - C25BNB240T](#)



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com

© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)