

# Eaton C25DNF240B

Catalog Number: C25DNF240B

Eaton definite purpose contactor, Quick, 40A, 208-240 Vac, 50/60 Hz, Open with metal mounting plate, 15-50A, two- and three-pole, 40A, Contactor, 2P, 50A, Box lugs (posidrive setscrew) and quick connect terminals (side-by-side), Non-reversing

## General specifications

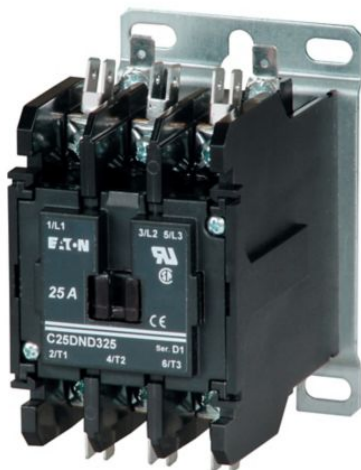


Photo is representative

<b>Product Name</b>	<b>Catalog Number</b>
Eaton definite purpose contactor	C25DNF240B
<b>UPC</b>	<b>Product Length/Depth</b>
782116300402	3.35 in
<b>Product Height</b>	<b>Product Width</b>
3.75 in	2.4 in
<b>Product Weight</b>	<b>Warranty</b>
1.19 lb	1 year
<b>Compliances</b>	<b>Certifications</b>
RoHS Compliant	UL Recognized CSA Certified

## defaultTaxonomyAttributeLabel

### Amperage Rating

40A

### Number Of Poles

Two-pole

### Type

Non-reversing

### Coil

208-240 Vac

### Coil voltage

50/60 Hz

### Enclosure

Open with metal mounting plate

### Frame size

15-50 A, two-pole and three-pole

### Inductive full load

40 A

### Model

Contactors

### Resistive load

50 A

### Terminals

Box lugs (posidrive setscrew) and quick connect terminals (side-by-side)

### Connection

Quick

## Resources

### Catalogs

Eaton's Volume 5—Motor Control and Protection

### Drawings

C25DNF2 3D Model Xchange

C25DNF2 AutoCAD 2D Footprint

C25DNF2 2D PDF

C25DNF2 2D Drawing Xchange

C25DNF2 3D Inventor

C25DNF2 AutoCAD 2D Footprint (mm)

### Specifications and datasheets

Eaton Specification Sheet - C25DNF240B



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com  
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)