
 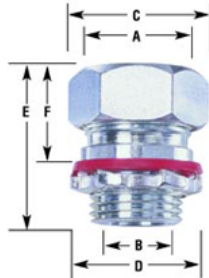


US Steel

Images



[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: .250-.350
Dimension B in Inches: .640
Dimension C in Inches: 1.210
Dimension D in Inches: .975
Dimension E in Inches: 1-5/16
Dimension F in Inches: 13/16

Application

These watertight fittings are designed for both indoor and outdoor applications. All fittings can be used in chemical and treatment plants as well as for offshore applications. Straight connector for use with portable cord provides liquid tight and water tight protection. Typical applications include wiring of motors, transformers, advanced machinery, refrigeration, and tools.

Product Information

Material: Steel
Finish: Zinc Electro-Plate

Certifications & Codes:

NEMA Standard: FB-1
UL File Number: E11259, cULus
UL Standard: UL514B
UNSPSC: 39121431

Catalog ID: CG770-350

UPC Number: 78174727702

Description: Connector, cord grip, straight, steel, k.o. size-1/2", cord range .250-.350

Application: These watertight fittings are designed for both indoor and outdoor applications. All fittings can be used in chemical and treatment plants as well as for offshore applications. Straight connector for use with portable cord provides liquid tight and water tight protection. Typical applications include wiring of motors, transformers, advanced machinery, refrigeration, and tools.

Trade Size: 1/2"

Country of Manufacture: USA

Std Pkg Qty: 250

Unit Qty: 25