
 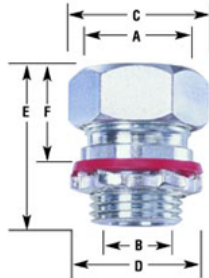


US Steel

Images



[Download Photo Image](#)

[Download Dimensional Image](#)

Dimension A in Inches: .250-.350
Dimension B in Inches: .687
Dimension C in Inches: 1.210
Dimension D in Inches: 1.220
Dimension E in Inches: 1-5/16
Dimension F in Inches: 13/16

Application

These watertight fittings are designed for both indoor and outdoor applications. All fittings can be used in chemical and treatment plants as well as for offshore applications. Straight connector for use with portable cord provides liquid tight and water tight protection. Typical applications include wiring of motors, transformers, advanced machinery, refrigeration, and tools.

Product Information

Material: Steel
Finish: Zinc Electro-Plate

Certifications & Codes:

NEMA Standard: FB-1
UL File Number: E11259, cULus
UL Standard: UL514B
UNSPSC: 39121431

Catalog ID: CG771-350

UPC Number: 78174727712

Description: Connector, cord grip, straight, steel, k.o. size-3/4", cord range .250-.350

Application: These watertight fittings are designed for both indoor and outdoor applications. All fittings can be used in chemical and treatment plants as well as for offshore applications. Straight connector for use with portable cord provides liquid tight and water tight protection. Typical applications include wiring of motors, transformers, advanced machinery, refrigeration, and tools.

Trade Size: 3/4"

Country of Manufacture: USA

Std Pkg Qty: 100

Unit Qty: 10