


Eaton CH16L125R

Catalog Number: CH16L125R

Eaton CH main lug loadcenters, Cover included, Main lug only, 125A, B, Copper, NEMA 3R, Metallic, Overhead, CH, 16, 16, Three-wire, Single-phase, 120/240 V, #6-2/0 AWG

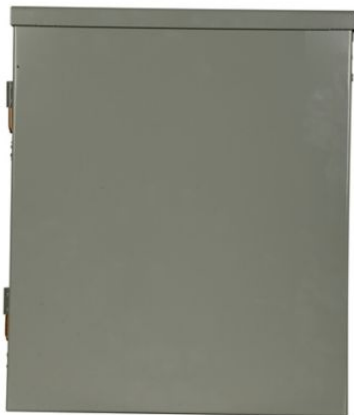

General specifications

Product Name	Catalog Number
Eaton CH main lug loadcenter	CH16L125R
UPC	Product Length/Depth
782113097480	16.75 in
Product Height	Product Width
5.19 in	14.31 in
Product Weight	Warranty
16 lb	Limited lifetime
Certifications	Catalog Notes
UL 50 UL 67	Suitable for use as service equipment when not more than six service disconnecting mains are provided or when not used as a lighting and appliance panelboard. Rainproof panels are furnished with hub closure plates. For rainproof hubs.

defaultTaxonomyAttributeLabel

Special features

Cover included

Type

Main lug only

Amperage Rating

125 A

Bus material

Copper

Feed type

Overhead

Main circuit breaker

CH

Number of circuits

16

Number of spaces

16

Phase

Single-phase

Voltage rating

120/240 V

Wire size

#6-2/0 AWG

Box size

B

Enclosure

NEMA 3R

Enclosure material

Metallic

Number of wires

3

Resources

Brochures

Type CH Circuit Breakers and Loadcenters

Loadcenters and Circuit Breakers

Catalogs

Eaton's Volume 1—Residential and Light Commercial

Drawings

Dimensional Drawing - CH 3/4 LOADCENTER, MAIN LUG ONLY, OUTDOOR NEMA 3R, 120/240 VAC, 1 PH

Installation instructions

Cutler-Hammer Type CH and BR Loadcenters - Instructions

Multimedia

AFCI Educational Video

Specifications and datasheets

Eaton Specification Sheet - CH16L125R



Eaton Corporation plc
Eaton House
30 Pembroke Road
Dublin 4, Ireland
Eaton.com
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)