


# Eaton CH42N225R

Catalog Number: CH42N225R

Eaton CH 3/4-inch main loadcenter, single-phase, 42 circuits, 42-pole, #2-300 kcmil wire, 225A, NEMA 3R

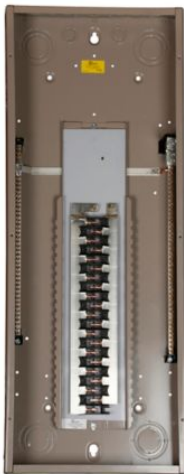

## General specifications

Product Name	Catalog Number
Eaton CH convertible loadcenter	CH42N225R
UPC	Product Length/Depth
782113098548	37 in
Product Height	Product Width
5.19 in	14.31 in
Product Weight	Warranty
38.5 lb	Limited lifetime
Certifications	Catalog Notes
UL 67 UL 50	Furnished with hub closure plates.

## defaultTaxonomyAttributeLabel

### Special features

Standard

### Type

Convertible

### Amperage Rating

225 A

### Bus material

Copper

### Feed type

Overhead

### Main circuit breaker

CH

### Number of circuits

42

### Number of spaces

42

### Phase

Single-phase

### Wire size

#2 AWG-300 kcmil

### Box size

K

### Enclosure

NEMA 3R

### Enclosure material

Metallic

### Interrupt rating

10 kAIC

### Number of wires

3

## Resources

### Brochures

Type CH Circuit Breakers and Loadcenters

Loadcenters and Circuit Breakers

### Catalogs

Eaton's Volume 1—Residential and Light Commercial

### Drawings

Dimensional Drawing - CH 3/4 LOADCENTER, CSR CONVERTIBLE, OUTDOOR NEMA 3R, 120/240 VAC, 1 PH

### Installation instructions

Cutler-Hammer Type CH and BR Loadcenters - Instructions

### Multimedia

AFCI Educational Video

### Specifications and datasheets

Eaton Specification Sheet - CH42N225R



Eaton Corporation plc  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com  
© 2024 Eaton. All Rights Reserved.

Eaton is a registered trademark.

All other trademarks are property of their respective owners.



[Eaton.com/socialmedia](https://www.eaton.com/socialmedia)