


# Specifications



Photo is representative

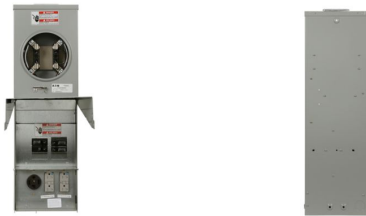

## Eaton CHR8N8NSU

Eaton pedestal mount metered, Pos 1: Gnd fault, Pos 2: Non-gnd fault, Pos 3: None, Bottom, Surface, Circuits: 4, Weather-resist center and left receptacle, Center: NEMA 5-20R2GFI WR, Left: NEMA 5-20R2GFI WR, Right: None, Ringless

### General specifications

<b>PRODUCT NAME</b>	Eaton pedestal mount metered
<b>CATALOG NUMBER</b>	CHR8N8NSU
<b>UPC</b>	786685404202
<b>PRODUCT LENGTH/DEPTH</b>	7.25 in
<b>PRODUCT HEIGHT</b>	31 in
<b>PRODUCT WIDTH</b>	10 in
<b>PRODUCT WEIGHT</b>	30 lb
<b>WARRANTY</b>	Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.
<b>CERTIFICATIONS</b>	UL 231 UL Listed file E163588



Powering Business Worldwide

## Product specifications

<b>SPECIAL FEATURES</b>	Water resistant left/center receptacle
<b>TYPE</b>	Metered-ringless
<b>CIRCUIT BREAKER POSITION 1</b>	Ground fault
<b>CIRCUIT BREAKER POSITION 2</b>	Non-ground fault
<b>CIRCUIT BREAKER POSITION 3</b>	None
<b>RECEPTACLE CENTER</b>	NEMA 5-20R2GFI
<b>RECEPTACLE LEFT</b>	NEMA 5-20R2GFI
<b>RECEPTACLE RIGHT</b>	None
<b>FEED TYPE</b>	Bottom
<b>MOUNTING</b>	Surface
<b>NUMBER OF CIRCUITS</b>	4

## Resources

CATALOGS	<a href="#">Residential and Light Commercial, Power Pedestals, Volume 1 Tab 5</a>
SPECIFICATIONS AND DATASHEETS	<a href="#">Eaton Specification Sheet - CHR8N8NSU</a>

PROJECT NAME:

PROJECT NUMBER:

PREPARED BY:

DATE:



**Eaton Corporation plc**  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com

Follow us on social media to get the latest product and support information.




© 2025 Eaton. All Rights Reserved.

# Specifications



Photo is representative

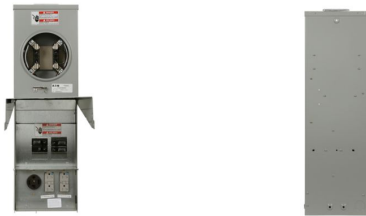

## Eaton CHR8N8NSU

Eaton pedestal mount metered, Pos 1: Gnd fault, Pos 2: Non-gnd fault, Pos 3: None, Bottom, Surface, Circuits: 4, Weather-resist center and left receptacle, Center: NEMA 5-20R2GFI WR, Left: NEMA 5-20R2GFI WR, Right: None, Ringless

### General specifications

<b>PRODUCT NAME</b>	Eaton pedestal mount metered
<b>CATALOG NUMBER</b>	CHR8N8NSU
<b>UPC</b>	786685404202
<b>PRODUCT LENGTH/DEPTH</b>	7.25 in
<b>PRODUCT HEIGHT</b>	31 in
<b>PRODUCT WIDTH</b>	10 in
<b>PRODUCT WEIGHT</b>	30 lb
<b>WARRANTY</b>	Eaton Selling Policy 25-000, one (1) year from the date of installation of the Product or eighteen (18) months from the date of shipment of the Product, whichever occurs first.
<b>CERTIFICATIONS</b>	UL 231 UL Listed file E163588



Powering Business Worldwide

## Product specifications

<b>SPECIAL FEATURES</b>	Water resistant left/center receptacle
<b>TYPE</b>	Metered-ringless
<b>CIRCUIT BREAKER POSITION 1</b>	Ground fault
<b>CIRCUIT BREAKER POSITION 2</b>	Non-ground fault
<b>CIRCUIT BREAKER POSITION 3</b>	None
<b>RECEPTACLE CENTER</b>	NEMA 5-20R2GFI
<b>RECEPTACLE LEFT</b>	NEMA 5-20R2GFI
<b>RECEPTACLE RIGHT</b>	None
<b>FEED TYPE</b>	Bottom
<b>MOUNTING</b>	Surface
<b>NUMBER OF CIRCUITS</b>	4

## Resources

CATALOGS	<a href="#">Residential and Light Commercial, Power Pedestals, Volume 1 Tab 5</a>
SPECIFICATIONS AND DATASHEETS	<a href="#">Eaton Specification Sheet - CHR8N8NSU</a>

PROJECT NAME:

PROJECT NUMBER:

PREPARED BY:

DATE:



**Eaton Corporation plc**  
Eaton House  
30 Pembroke Road  
Dublin 4, Ireland  
Eaton.com

Follow us on social media to get the latest product and support information.



© 2025 Eaton. All Rights Reserved.